

Louvered Hanging Systems

Customizable, flexible vertical storage for hanging bins


- This universal hanging surface provides easy placement and configuration of multiple sizes and styles of bins
- Wall-mounted panels keep items out of the way, off the floor and off the work table
- Create storage space anywhere! Flexible solutions for any environment



30632GY with 30210RED, LPP6NL



30636BEIGE with 30320BLUE

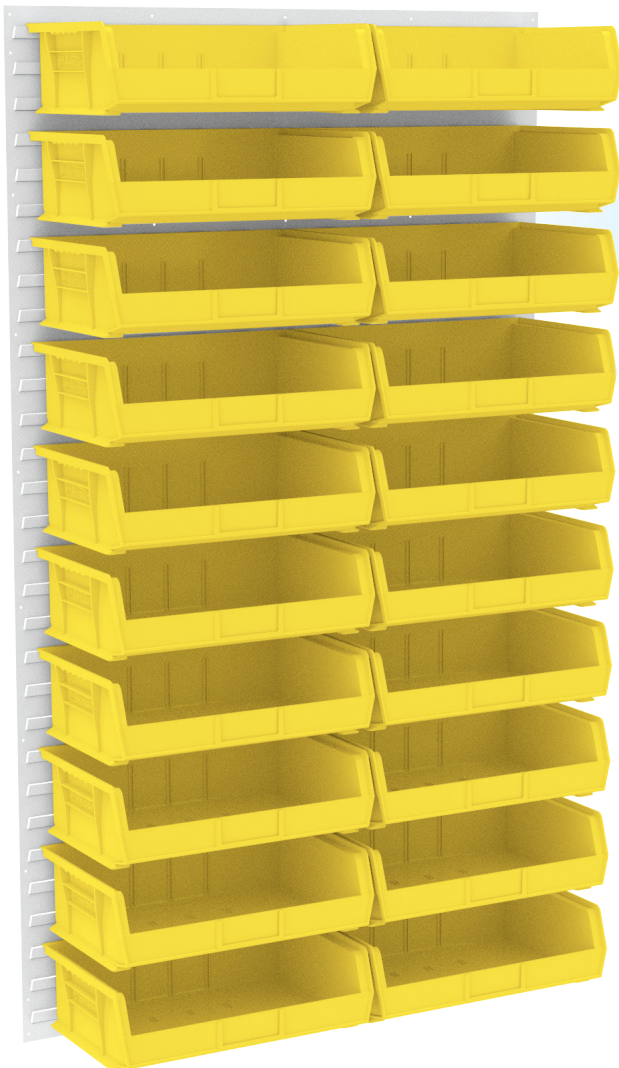

Select Panels now available in Textured White



Easy Assembly!

Models 30638, 30658, 30661, 30676, 30650GY, 30656GY, 30606GY & 30607GY are full louvered panels pre-mounted to a heavy-duty frame, saving assembly time.


COLORS

Gray, Beige, Textured White




30161TEXWHT with 30255YELLOW


WALL PANELS

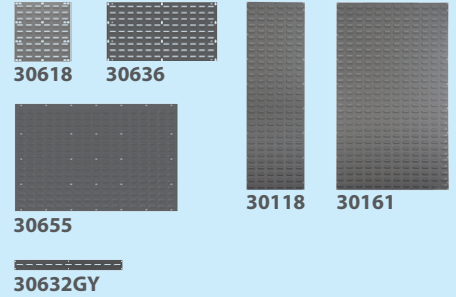

HEAVY-DUTY FLOOR RACKS

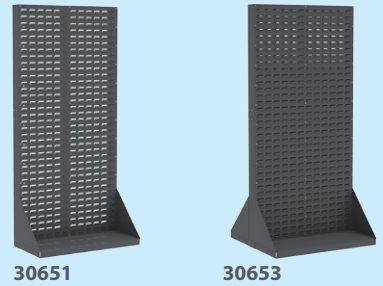

RIVET FLOOR RACKS

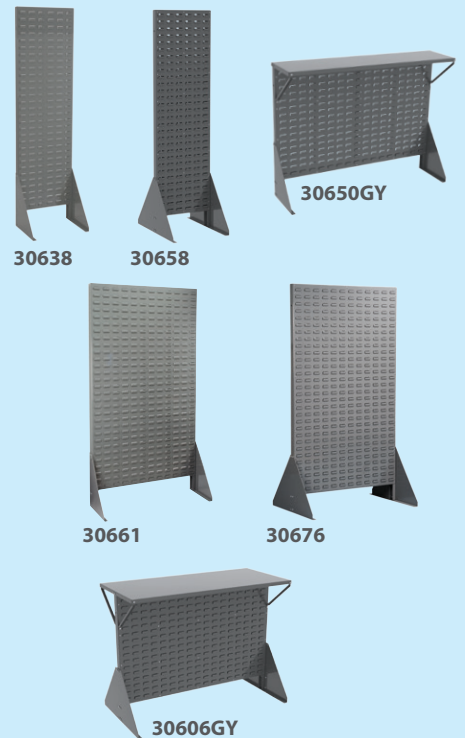

BENCH RACKS



AkroBin Louvered Hanging Systems			Dimensions (In.)				AkroBin Quantity to Fit Louvered Hanging System – AkroBins Model No.														
Model No.	Description	Ctn. Qty	L	W	H	Rack Wt. Cap. (lbs.)	30210	30220	30224	30230	30234	30235	30237	30239	30240	30250	30255	30260	30265	30270	30320
30618**	Louvered Wall Panel	4	18	5/16	19	160	16	16	12	9	9	3	6	4	4	2	3	1	2	1	–
30632**	Single Row Louvered Panel	2	31-15/16	5/16	3	80	7	7	7	5	5	2	5	3	3	1	1	2	3	1	–
30636**	Louvered Wall Panel	4	35-3/4	5/16	19	160	32	32	24	18	18	9	15	8	8	4	6	3	4	2	3
	2 Louvered Wall Panels		35-3/4	5/16	37	–	72	72	48	36	36	18	30	16	16	8	12	9	12	6	6
	3 Louvered Wall Panels		35-3/4	5/16	55	–	104	104	72	54	54	27	45	24	24	12	18	12	20	8	9
	4 Louvered Wall Panels		35-3/4	5/16	73	–	144	144	96	72	72	36	60	36	36	18	24	18	28	12	12
30655	Louvered Wall Panel	1	52	5/16	34-1/8	750	96	96	60	45	45	20	40	24	24	12	15	8	18	6	5
30161**	Louvered Wall Panel	1	36	5/16	61	1000	120	120	80	60	60	30	50	28	28	14	20	15	24	10	10
30118**	Louvered Wall Panel	1	18	5/16	61	500	60	60	40	30	30	10	20	14	14	7	10	5	12	5	–
30651	Heavy-Duty Single-Sided Floor Rack	1	35-3/4	17	75-1/8	1000	144	144	96	72	72	36	60	36	36	18	24	18	28	12	12
30653	Heavy-Duty Double-Sided Floor Rack	1	35-3/4	32	75-1/8	2000	288	288	192	144	144	72	120	72	72	36	48	36	56	24	24
30638	Single-Sided Rivet Floor Rack	1	18	13-1/2	66-3/8	250	60	60	40	30	30	10	20	14	14	7	10	5	12	5	–
30658	Double-Sided Rivet Floor Rack	1	18	25	66-3/8	500	120	120	80	60	60	20	40	28	28	14	20	10	24	10	–
30661*	Single-Sided Rivet Floor Rack	1	36-3/16	13-1/2	66-3/8	500	120	120	80	60	60	30	50	28	28	14	20	15	24	10	10
30676*	Double-Sided Rivet Floor Rack	1	36-3/16	25	66-3/8	1000	240	240	160	120	120	60	100	56	56	28	40	30	48	20	20
30653DOLLY	Mobile Kit for 30653	1	–	–	–	500	–	–	–	–	–	–	–	–	–	–	–	–	–	–	–
LVDMMOBILE	Mobile Kit for 30676	1	–	–	–	1500	–	–	–	–	–	–	–	–	–	–	–	–	–	–	–
30661DOLLYGY	Gray Floor Rack Dolly for 30661	1	37	24	6	500	–	–	–	–	–	–	–	–	–	–	–	–	–	–	–
30661DOLLYBE	Beige Floor Rack Dolly for 30661	1	37	24	6	500	–	–	–	–	–	–	–	–	–	–	–	–	–	–	–

*Also available in Beige. **Also available in Textured White. Specify color when ordering. Beige = BEIGE, White = TEXWHT, GY = Gray.

Louvered Bench Rack			Dimensions (In.)				AkroBin Quantity to Fit Louvered Hanging System – AkroBins Model No.													
Model No.	Description	Ctn. Qty	L	W	H	Rack Wt. Cap. (lbs.)	30210	30220	30224	30230	30234	30235	30237	30239	30240	30250	30255	30260	30265	30320
98600*	Bench Rack	1	27-15/16	8-9/16	19-9/16	120	30	30	18	12	12	6	12	6	6	2	3	2	6	–
98636	Bench Rack	1	36	8	20	120	40	40	24	18	18	9	15	8	8	4	6	3	8	3

*Also available in Beige. Specify color when ordering. Beige = BEIGE. Gray requires no suffix.

Low Profile Floor Rack – Single-Sided		Rack Dimensions (In.)			Bin Dimensions (In.)				Wt. Capacity (Lbs.)		
Model No.	Description	W	H	D	Bin Model No.	L	W	H	Bin Qty.	Panel/Top	Colors
30650GY	Low Profile Floor Rack	52-5/8	40	13-1/2	–	–	–	–	–	500/250	–
30650GY240	Low Profile Floor Rack	52-5/8	40	13-1/2	30240	14-3/4	8-1/4	7	24	500/250	B, R, Y, SC
30650GY250	Low Profile Floor Rack	52-5/8	40	13-1/2	30250	14-3/4	16-1/2	7	12	500/250	B, R, Y, SC
30650GYASST	Low Profile Floor Rack	52-5/8	40	13-1/2	30240 / 30250	See Above	–	–	12 / 6	500/250	B, R, Y, SC
30656GY	Low Profile Floor Rack no Shelf	52-5/8	39-7/8	13-1/2	–	–	–	–	–	500	B, R, Y, SC
30656GY240	Low Profile Floor Rack no Shelf	52-5/8	39-7/8	13-1/2	30240	14-3/4	8-1/4	7	24	500	B, R, Y, SC
30656GY250	Low Profile Floor Rack no Shelf	52-5/8	39-7/8	13-1/2	30250	14-3/4	16-1/2	7	12	500	B, R, Y, SC
30656GYASST	Low Profile Floor Rack no Shelf	52-5/8	39-7/8	13-1/2	30240 / 30250	See Above	–	–	12 / 6	500	B, R, Y, SC

Rack available in Gray only. Specify color of bins when ordering. B=Blue, R=Red, Y=Yellow, SC=Clear.

Low Profile Floor Rack – Double-Sided		Rack Dimensions (In.)			Bin Dimensions (In.)				Wt. Capacity (Lbs.)		
Model No.	Description	W	H	D	Bin Model No.	L	W	H	Bin Qty.	Panel/Top	Colors
30606GY	Low Profile Floor Rack	52-5/8	40	27	–	–	–	–	–	500 per side/250	–
30606GY240	Low Profile Floor Rack	52-5/8	40	27	30240	14-3/4	8-1/4	7	48	500 per side/250	B, R, Y, SC
30606GY250	Low Profile Floor Rack	52-5/8	40	27	30250	14-3/4	16-1/2	7	24	500 per side/250	B, R, Y, SC
30606GYASST	Low Profile Floor Rack	52-5/8	40	27	30240 / 30250	See Above	–	–	24 / 12	500 per side/250	B, R, Y, SC
30607GY	Low Profile Floor Rack no Shelf	52-5/8	39-7/8	27	–	–	–	–	–	500	B, R, Y, SC
30607GY240	Low Profile Floor Rack no Shelf	52-5/8	39-7/8	27	30240	14-3/4	8-1/4	7	48	500	B, R, Y, SC
30607GY250	Low Profile Floor Rack no Shelf	52-5/8	39-7/8	27	30250	14-3/4	16-1/2	7	24	500	B, R, Y, SC
30607GYASST	Low Profile Floor Rack no Shelf	52-5/8	39-7/8	27	30240 / 30250	See Above	–	–	24 / 12	500	B, R, Y, SC
30606DOLLY	Dolly for 30606 or 30607	53	5-7/8	27-1/2	–	–	–	–	–	3600*	–

Rack available in Gray only. Specify color of bins when ordering. B=Blue, R=Red, Y=Yellow, SC=Clear. *Do not exceed weight capacity of Low-Profile Rack.

InSight Louvered Panel Systems		
Model No.	Description	Bin Qty.
30636BEIGE A1	35-3/4" x 19" Louvered Wall Panel with 305A1	32
30636BEIGE A3	35-3/4" x 19" Louvered Wall Panel with 305A3	32
30636BEIGE A5	35-3/4" x 19" Louvered Wall Panel with 305A5	32
30636BEIGE B1	35-3/4" x 19" Louvered Wall Panel with 305B1	18



30607GY with 30606DOLLY



akro-mils.com

1293 South Main Street, Akron, Ohio 44301 • Tel: 800.253.2467 • Fax: 330.761.6348 • sales@akro-mils.com
 In Canada: Ak-West, Inc. • Tel: 877.979.8940 • Fax: 403.225.1696 • sales@ak-westinc.com • ak-westinc.com