


Dismantling tool for data cables

16
65

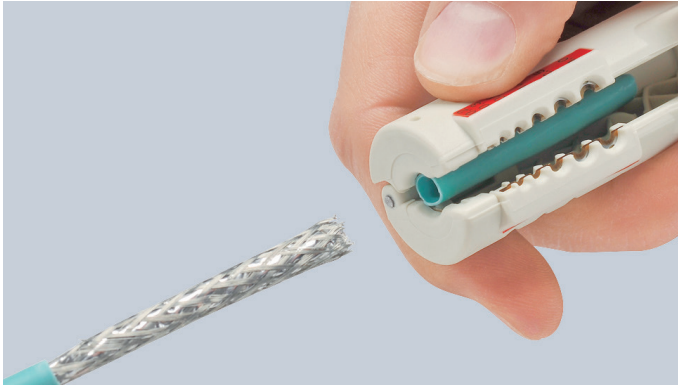

- > for stripping UTP and STP data cables with diameters of 11/64" to 25/64" (4.5 to 10.0 mm)
- > stripping device for 0.2 / 0.3 / 0.8 / 1.5 / 2.5 / 4.0 mm²
- > double shell, folding back stripping tool
- > with opening spring and locking lever
- > clip for safe transport
- > body: plastic, fiberglass-reinforced
- > blades: special tool steel; oil-hardened, TiN-coated

16 65 125 SB
M



Product Number	Packaging	↔ Inch mm		Cable type	Stripping capacities Ø Inch Ø mm	Stripping capacities mm ²	⚖ lbs
16 65 125 SB	X	5 125	M	CAT 5, CAT 6, CAT 7, Twisted-Pair (UTP/STP)	11/16 - 25/64 4.5 - 10.0	0.2 - 4.0	0.11

Universal Dismantling Tools

16
8

- > for dismantling and stripping all common round and damp-proof installation cables between 3 x 1.5 mm² up to 5 x 2.5 mm²
- > for use in conduit and distribution boxes
- > double shell, folding back stripping tool
- > with opening spring and locking lever
- > clip for safe transport
- > body: plastic, fiberglass-reinforced

16 85 125 SB

With additional blade for longitudinal cuts; telescopic blade inside; stripping device for 0.2 / 0.3 / 0.8 / 1.5 / 2.5 / 4.0 mm²; with integrated cable guide for longitudinal cut. This enables rigid insulation (e.g. halogen-free) to be stripped easily



16 80 125 SB
M



16 85 125 SB
M



Product Number	Packaging	↔ Inch mm		Stripping capacities Ø mm	Stripping capacities mm ²	Cable type	⚖ lbs
16 80 125 SB	X	5 125	M	8.0 - 13.0		round cable. e.g.: 3 x 1.5 mm ² up to 5 x 2.5 mm ²	0.12
16 85 125 SB	X	5 125	M	8.0 - 13.0	0.2 - 4.0	round cable. e.g.: 3 x 1.5 mm ² up to 5 x 2.5 mm ²	0.1