



**MCR
SAFETY**

6912

**Memphis NeoMax
Supported / Dipped gloves
Specification Sheet**

PRODUCT DESCRIPTION:

Not only does the NeoMax have a great name, but it offer outstanding protection. The 6912 features a 12 inch green double dipped glove with a brushed interlock liner. The sandy finish helps you get a grip and the lining is treated with ActiFresh® that will prevent bacterial build up and resist molds and mildew. Go to the Max with NeoMax™.

FEATURES:

- Green Double Dipped Neoprene
- 100% Cotton Brushed Interlock Liner
- Treated with Actifresh®
- 12 Inch Length
- Sandy Finish
- Component materials comply with all federal regulations for food contact

APPLICATIONS:

Oil and Gas Industry, Agriculture, Construction, Farming, Janitorial , Sanitation, Petrochemical industries, Food



TECHNICAL DATA FOR: 6912

Series	Memphis NeoMax	Overall Length	12 in.
Material Group	Supported	EN 388 : CE Score - Abrasion	2
Product Type	Supported / Dipped gloves	EN 388 : CE Score - Cut	1
Glove Size	Large	EN 388 : CE Score - Tear	2
Material	Neoprene	EN 388 : CE Score - Puncture	1
Grade	Industrial Grade	FDA Accepted Materials	FDA Compliant
Lining	Brushed Interlock		
Thumb Style	Wing		

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com


©2018 MCR Safety - All Rights Reserved



MCR
SAFETY

6912

Memphis NeoMax Supported / Dipped gloves Specification Sheet

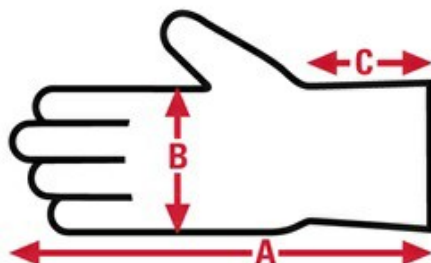

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
6912L	Large	12.160	6.200	N/A	31.668 lb.	5.278
6912M	Medium	11.840	6.200	N/A	28.722 lb.	4.787
6912S	Small	11.680	5.680	N/A	24.798 lb.	4.133
6912XL	X - Large	12.320	6.200	N/A	31.740 lb.	5.290

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved