


RED BRASS

90° STREET ELBOW

Features

- 125 Class
- 100% Inspected and tested
- Max pressure 150 PSI
- Temperature -65° to 250°F

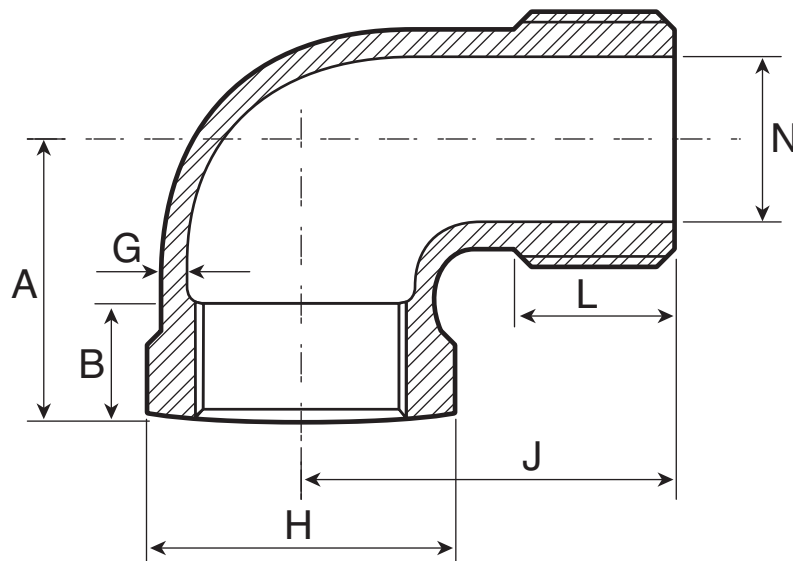

Part No.	Size	
1VEV6	1/8"	Threaded
1VEV7	1/4"	Threaded
1VEV9	3/8"	Threaded
1VEW2	1/2"	Threaded
1VEW3	3/4"	Threaded
1VEW4	1"	Threaded
1VEW6	1-1/4"	Threaded
1VEW8	1-1/2"	Threaded
1VEX1	2"	Threaded

- Bronze material meets ANSI/ASTM B62 standard
- Dimensions meet ANSI/ASME B16.15-1985 standard
- Threads meet ANSI B1.20.1

Dimensions are in inches

Part No.	Size	A	B	G	H	J	L	N
1VEV6	1/8"	0.54	0.25	0.08	0.67	0.92	0.27	0.22
1VEV7	1/4"	0.71	0.32	0.08	0.81	1.11	0.41	0.28
1VEV9	3/8"	0.82	0.36	0.09	1.00	1.24	0.41	0.40
1VEW2	1/2"	1.01	0.43	0.09	1.17	1.48	0.54	0.53
1VEW3	3/4"	1.18	0.50	0.10	1.42	1.65	0.55	0.72
1VEW4	1"	1.43	0.58	0.11	1.72	1.98	0.69	0.93
1VEW6	1-1/4"	1.69	0.67	0.12	2.10	2.24	0.71	1.25
1VEW8	1-1/2"	1.84	0.70	0.13	2.38	2.46	0.71	1.47
1VEX1	2"	2.12	0.75	0.15	2.92	2.88	0.76	1.91