


RED BRASS

HEX BUSHING

Features

- 125 Class
- 100% Inspected and tested
- Max Pressure 150 PSI
- Temperature -65 to 250°F

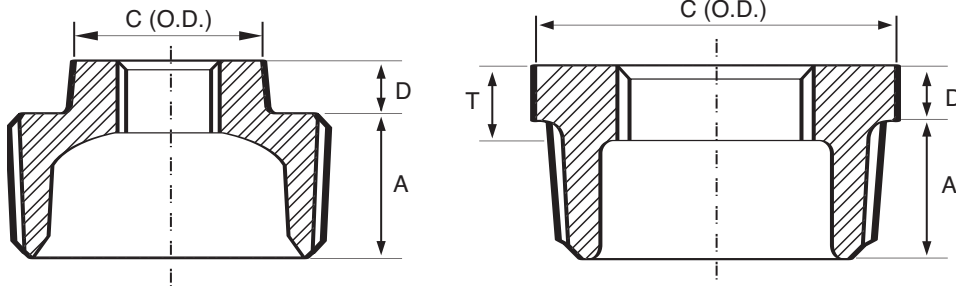

Dimensions are in inches

Part No.	Size	A	T	D	C
1VFB3	1/4"x1/8"	0.44	0.26	0.14	0.64
1VFB5	3/8"x1/8"	0.48	0.25	0.16	0.68
1VFB7	3/8"x1/4"	0.48	0.40	0.16	0.68
1VFB9	1/2"x1/8"	0.56	0.25	0.19	0.87
1VFB2	1/2"x1/4"	0.56	0.32	0.19	0.87
1VFB4	1/2"x3/8"	0.56	0.41	0.19	0.87
1VFB6	3/4"x1/8"	0.63	0.32	0.22	1.15
1VFB8	3/4"x1/4"	0.63	0.32	0.22	1.15
1VFB1	3/4"x3/8"	0.63	0.36	0.22	1.15
1VFB3	3/4"x1/2"	0.63	0.53	0.22	1.15
1VFB5	1"x1/4"	0.71	0.41	0.28	1.46
1VFB7	1"x3/8"	0.75	0.36	0.30	1.12
1VFB9	1"x1/2"	0.75	0.43	0.25	1.42
1VFB2	1"x3/4"	0.75	0.50	0.25	1.42
1VFB4	1-1/4"x3/4"	0.80	0.50	0.28	1.76
1VFB6	1-1/4"x1"	0.80	0.58	0.28	1.76
1VFB8	1-1/2"x3/4"	0.83	0.50	0.37	1.63
1VGA1	1-1/2"x1"	0.83	0.58	0.31	2.00
1VGA3	1-1/2"x1-1/4"	0.83	0.71	0.31	2.00
1VGA5	2"x3/4"	0.89	0.56	0.43	2.50
1VGA7	2"x1"	0.88	0.58	0.41	2.50
1VGA9	2"x1-1/4"	0.88	0.67	0.34	2.48
1VGB2	2"x1-1/2"	0.88	0.70	0.34	2.48
1VGB4	2-1/2"x2"	1.07	0.75	0.37	3.07
1VGB6	3"x2"	1.13	0.75	0.48	3.67
1VGB8	3"x2-1/2"	1.13	0.92	0.40	3.68
1VGC1	4"x3"	1.22	0.98	0.50	4.58



Part No.	Size	
1VFB3	1/4"x1/8"	Threaded
1VFB5	3/8"x1/8"	Threaded
1VFB7	3/8"x1/4"	Threaded
1VFB9	1/2"x1/8"	Threaded
1VFB2	1/2"x1/4"	Threaded
1VFB4	1/2"x3/8"	Threaded
1VFB6	3/4"x1/8"	Threaded
1VFB8	3/4"x1/4"	Threaded
1VFB1	3/4"x3/8"	Threaded
1VFB3	3/4"x1/2"	Threaded
1VFB5	1"x1/4"	Threaded
1VFB7	1"x3/8"	Threaded
1VFB9	1"x1/2"	Threaded
1VFB2	1"x3/4"	Threaded
1VFB4	1-1/4"x3/4"	Threaded
1VFB6	1-1/4"x1"	Threaded
1VFB8	1-1/2"x3/4"	Threaded
1VGA1	1-1/2"x1"	Threaded
1VGA3	1-1/2"x1-1/4"	Threaded
1VGA5	2"x3/4"	Threaded
1VGA7	2"x1"	Threaded
1VGA9	2"x1-1/4"	Threaded
1VGB2	2"x1-1/2"	Threaded
1VGB4	2-1/2"x2"	Threaded
1VGB6	3"x2"	Threaded
1VGB8	3"x2-1/2"	Threaded
1VGC1	4"x3"	Threaded

- Bronze material meets ANSI/ASTM B62 standard
- Threads meet ANSI B1.20.1