

# Straight Blade Devices



**15A, 125V,  
2 Pole, 2 Wire Non-Grounding,  
Valise® Plugs**

**IP20**  
SUITABILITY




**15A 125V  
NEMA 1-15R  
UL CSA  
0.5 HP**




**15A 125V  
NEMA 1-15P  
UL CSA  
0.5 HP**

Description	Cord Diameter	Catalog Number
Yellow nylon, non-polarized.	.218"-.385" (5.5-9.8)	- <b>HBL5865VY</b>
Yellow nylon, polarized.	.218"-.385" (5.5-9.8)	- <b>HBL5866VY</b>
Black nylon, polarized.	Type 17/2 "SVT" cord	- <b>HBL5867VBLK</b>

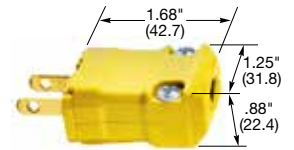


**HBL5865VY**

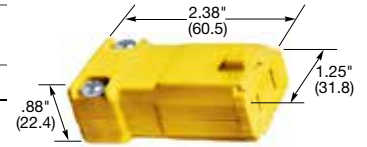

**HBL5866VY**

## Valise® Connector Bodies

Description	Cord Diameter	Catalog Number
Yellow nylon.	.218"-.385" (5.5-9.8)	<b>HBL5869VY</b> -

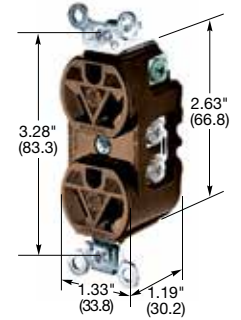

**HBL5869VY**



**15A, 277V AC,  
2 Pole, 3 Wire Grounding,  
Plugs**



**15A 277V AC  
NEMA 7-15R  
UL CSA  
2 HP**



**15A 277V AC  
NEMA 7-15P  
UL CSA  
2 HP**

Description	Cord Diameter	Catalog Number
Finger grip, black elastomer.	.31"-.43" (7.9-10.9)	- <b>HBL5929*</b>



**HBL5929**

## Receptacles and Connector Bodies

Description	Cord Diameter	Catalog Number
Receptacle, flush duplex, brown, back and side wired.	-	<b>HBL5302</b> -
Connector Body, phenolic and steel body.	.296"-.625" (7.5-15.9)	<b>HBL5324</b> -

Note: \*Not UL Listed.

Horsepower ratings are AC only.

See pages A-47 and A-48 for accessories.



**HBL9758VY**



**20A, 250V,  
2 Pole, 2 Wire Non-Grounding,  
Valise® Plugs**

**IP20**  
SUITABILITY




**20A 250V  
NEMA 2-20R  
UL Listed  
2 HP**



**20A 250V  
NEMA 2-20P  
UL Listed  
2 HP**

Description	Cord Diameter	Catalog Number
Yellow nylon.	.220"-.660" (5.6-16.8)	- <b>HBL9758VY</b>

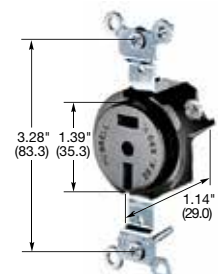

**HBL5552B**

## Receptacle, Single

Description	Catalog Number
Black phenolic.	<b>HBL5552B</b> -

Note: Horsepower ratings are AC only and apply to plugs and receptacles only.

See pages A-47 and A-48 for accessories.

Dimensions in Inches (mm)