

Midget Twist-Lock® Devices
 15A, 125V AC, 2 Pole, 2 Wire Non-Grounding
 Valise® Connector

HUBBELL

Features

- Fully insulated, abuse resistant nylon housing
- Insulation displacement terminals reduce wiring time
- Insulation displacement terminal



Ordering Information


Description	Cord Diameter	UPC Number	Catalog Number
Black Valise® connector, polarized.	.220"-.385"(5.6-9.8)	783585237251	HBL7464V

Listings

Listed to UL 498
 Certified to CSA C22.2 No.42

Specifications

Housing	Nylon
Contacts	Brass
Terminal Screws	#6 - 32 Steel (Philips / Slotted / Robertson)
Terminal Clamps	Steel - Nickel plated
Body Holding Screws	Steel - Zinc plated

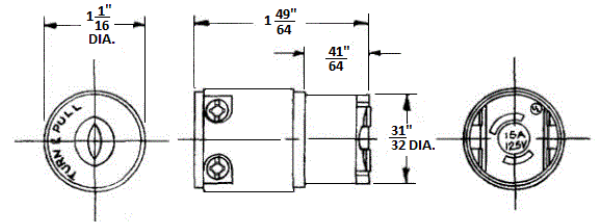

Performance

Electrical

Current Interrupting Certified for current interrupting at full rated current
 Dielectric Voltage Withstands 2,000V minimum

Mechanical

Terminal Accomodation #18 AWG - #14 AWG stranded copper wire only.
 Terminal Identification Terminals identified in accordance with UL 498

Environmental

Flammability HB or better per UL94/CSA 22.2 No.0.17
 Moisture Resistance IP20 Suitability
 Operating Temperatures Maximum Continuous 75°C Minimum -40°C (w/o impact)

Accessories

Valise® Plug	HBL7465V
Stainless Steel Flanged Inlet, Polarized Terminals	HBL7467
Stainless Steel Flanged Inlet, Not Polarized Terminals	HBL7466

Resources

Customer Use Drawing
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

