



Technical data

Voltage	U	240	V
Phase	1	~	
Frequency		60	Hz
Speed		1100	RPM
Power consumption	P _e	660	W
Nominal current	I	2.8	A
Maximum current	I	3.1	A
Capacitor		16/400	μF
Ambient temperature	T _{amb min/max}	-13...104	°F
Insulation Class		CL.F	
IP Class Fan		IP55	
Sound pressure level	L _p	72	db(A)
Sound pressure level distance		6.6	ft
Weight		45.2	Lbs.
Packing dimensions		31.5x31.1x15.6	inch

Fan details


Impeller blades	5
Impeller type	5
Impeller system	G
Impeller material	PG

Control options

Triac controller	Yes
Transformer	Yes
Frequency drive	No
Intelligent Fan Drive	No

Characteristics

0.00 in. wg	7121 CFM
0.20 in. wg	6297 CFM

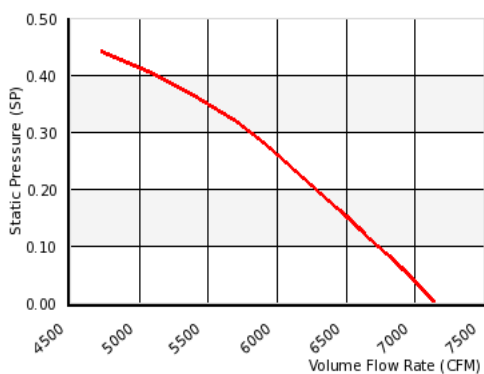


Please note: Picture may deviate from original product

Approval(s)




Wiring diagram - Fan

AA01 - 1 Phase - Standard - CCW

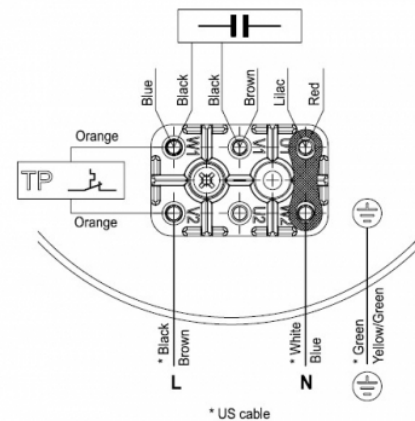

Dimensions

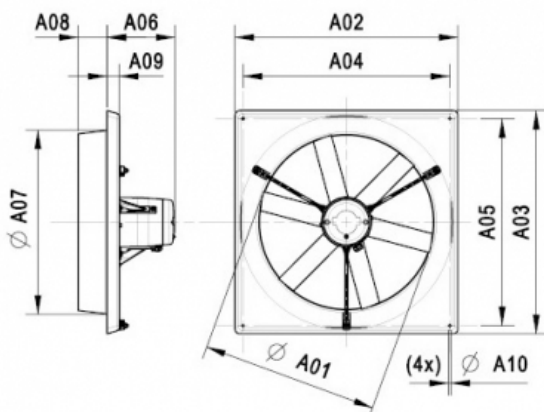

A01	25.4 inch
A02	30.5 inch
A03	30.5 inch
A04	28.2 inch
A05	28.2 inch
A06	9.7 inch
A07	26.4 inch
A08	4.1 inch
A09	1.6 inch
A10	0.4 inch