



Technical data

Voltage	U	240	V
Phase		1	~
Frequency		60	Hz
Speed		1680	RPM
Power consumption	P _e	110	W
Nominal current	I	0.6	A
Maximum current	I	0.8	A
Capacitor		02/400	µF
Ambient temperature	T _{amb min/max}	-13...104	°F
Insulation Class		CL.F	
IP Class Fan		IP55	
Sound pressure level	L _p	56	db(A)
Sound pressure level distance		6.6	ft
Weight		21.7	Lbs.
Packing dimensions		18.1x18.1x12.4	inch

Fan details


Impeller blades	6
Impeller type	3
Impeller system	C
Impeller material	PP

Control options

Triac controller	Yes
Transformer	Yes
Frequency drive	No
Intelligent Fan Drive	No

Characteristics

0.00 in. wg	1412 CFM
0.20 in. wg	1177 CFM

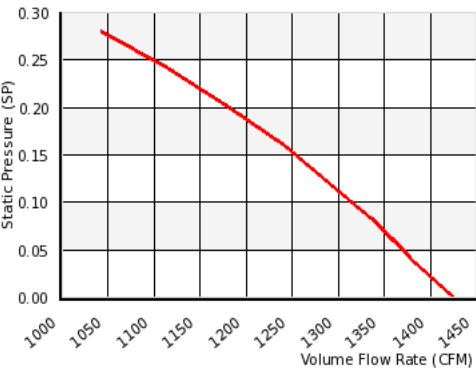


Please note: Picture may deviate from original product

Approval(s)




Wiring diagram - Fan

AA01 - 1 Phase - Standard - CCW

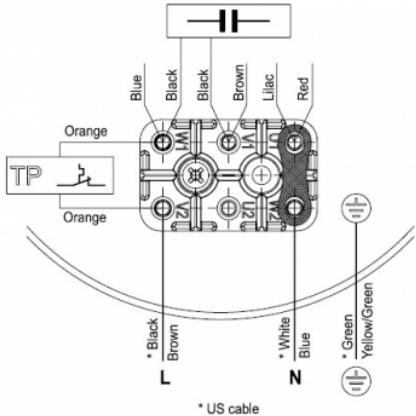

Dimensions

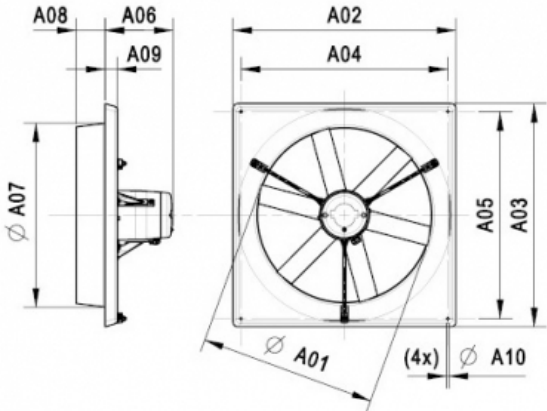

A01	12.3 inch
A02	17.4 inch
A03	17.4 inch
A04	15.6 inch
A05	15.6 inch
A06	7.6 inch
A07	13.4 inch
A08	3.3 inch
A09	1.4 inch
A10	0.3 inch