



Technical data

Voltage	U	240	V
Phase	1	~	
Frequency		60	Hz
Speed		1645	RPM
Power consumption	P _e	180	W
Nominal current	I	1.1	A
Maximum current	I	1.2	A
Capacitor		03/400	μF
Ambient temperature	T _{amb min/max}	-13...104	°F
Insulation Class		CL.F	
IP Class Fan		IP55	
Sound pressure level	L _p	59	db(A)
Sound pressure level distance		6.6	ft
Weight		21.1	Lbs.
Packing dimensions		18.1x18.1x12.4	inch

Fan details


Impeller blades	6
Impeller type	3
Impeller system	C
Impeller material	PP

Control options

Triac controller	Yes
Transformer	Yes
Frequency drive	No
Intelligent Fan Drive	No

Characteristics

0.00 in. wg	2148 CFM
0.20 in. wg	1824 CFM

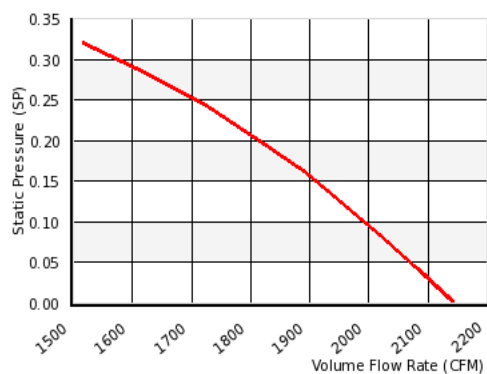


Please note: Picture may deviate from original product

Approval(s)




Wiring diagram - Fan

AA01 - 1 Phase - Standard - CCW

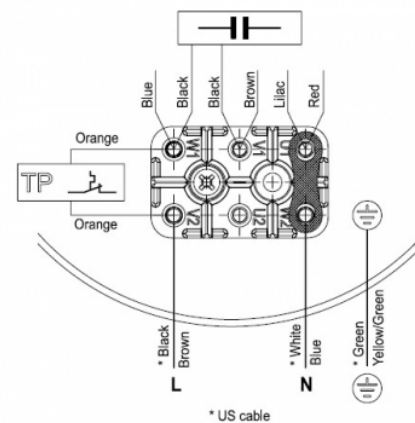

Dimensions

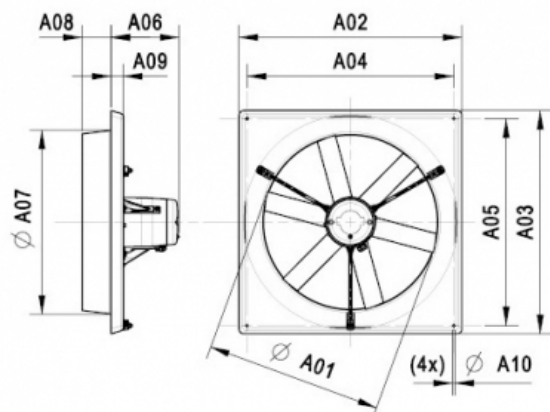

A01	14.3 inch
A02	19.4 inch
A03	19.4 inch
A04	17.5 inch
A05	17.5 inch
A06	7.6 inch
A07	15.4 inch
A08	3.3 inch
A09	1.4 inch
A10	0.3 inch