



Technical data

Voltage	U	265/460	V
Phase		3	~
Frequency		60	Hz
Speed		1650	RPM
Power consumption	P _e	340	W
Nominal current	I	1.4/0.8	A
Maximum current	I	1.4/0.8	A
Capacitor		-	μF
Ambient temperature	T _{amb min/max}	-13...104	°F
Insulation Class		CL.F	
IP Class Fan		IP55	
Weight		31.2	Lbs.
Packing dimensions		24.4x24.4x12.4	inch

Fan details


Impeller blades	6
Impeller type	3
Impeller system	C
Impeller material	PP

Control options

Triac controller	No
Transformer	Yes
Frequency drive	Yes
Intelligent Fan Drive	No

Characteristics

0.00 in. wg	3884 CFM
0.20 in. wg	3413 CFM

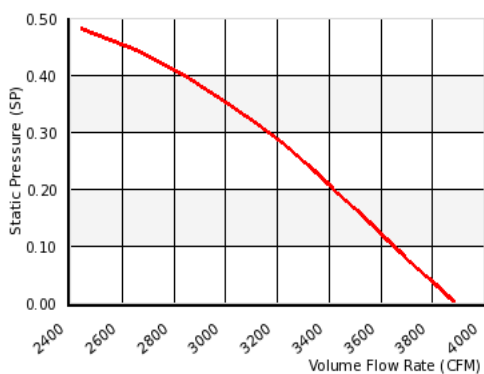


Please note: Picture may deviate from original product

Approval(s)




Wiring diagram - Fan

AB01 - 3 Phase - Star connected - CCW

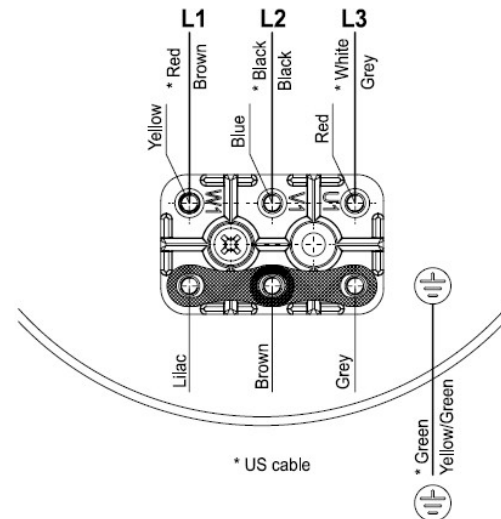

Dimensions

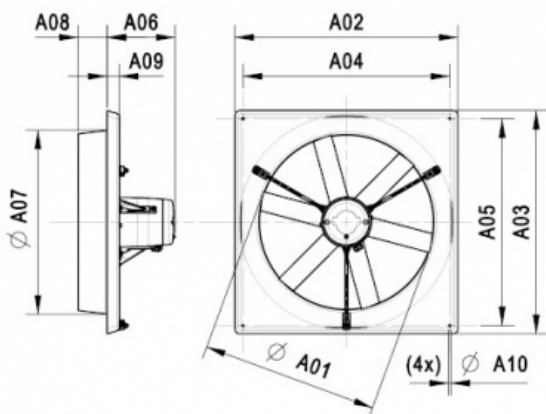

A01	18.1 inch
A02	23.3 inch
A03	23.3 inch
A04	21.5 inch
A05	21.5 inch
A06	9.7 inch
A07	19.3 inch
A08	3.3 inch
A09	1.4 inch
A10	0.3 inch