

Technical data

Voltage	U	265/460	V
Phase		3	~
Frequency		60	Hz
Speed		1080	RPM
Power consumption	P _e	790	W
Nominal current	I	2.6/1.5	A
Maximum current	I	2.8/1.6	A
Capacitor		-	µF
Ambient temperature	T _{amb min/max}	-13...104	°F
Insulation Class		CL.F	
IP Class Fan		IP55	
Weight		48.5	Lbs.
Packing dimensions		31.5x31.1x15.6	inch

Fan details


Impeller blades	4
Impeller type	5
Impeller system	G
Impeller material	PG

Control options

Triac controller	No
Transformer	Yes
Frequency drive	Yes
Intelligent Fan Drive	No

Characteristics

0.00 in. wg	8062 CFM
0.20 in. wg	6944 CFM

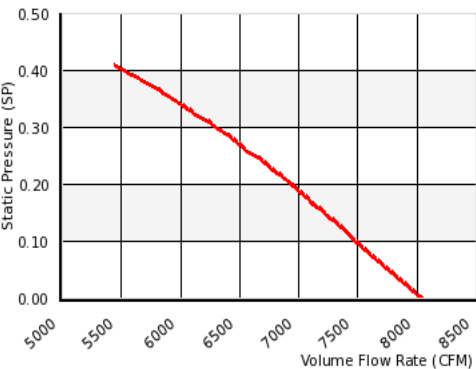


Please note: Picture may deviate from original product

Approval(s)




Wiring diagram - Fan

AB01 - 3 Phase - Star connected - CCW

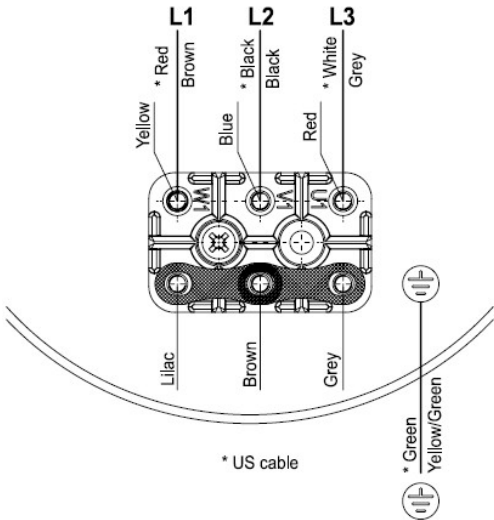

Dimensions

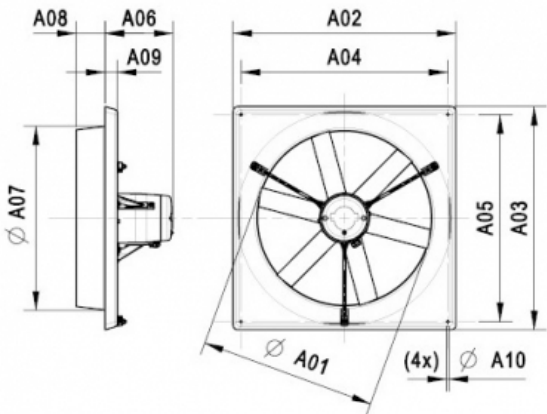

A01	25.4 inch
A02	30.5 inch
A03	30.5 inch
A04	28.2 inch
A05	28.2 inch
A06	9.7 inch
A07	26.4 inch
A08	4.1 inch
A09	1.6 inch
A10	0.4 inch