



Technical data

Voltage	U	265/460	V
Phase		3	~
Frequency		60	Hz
Speed		1640	RPM
Power consumption	P _e	2400	W
Nominal current	I	7.8/4.5	A
Maximum current	I	8.2/4.8	A
Capacitor		-	µF
Ambient temperature	T _{amb min/max}	-13...104	°F
Insulation Class		CL.F	
IP Class Fan		IP55	
Weight		59.1	Lbs.
Packing dimensions		34.3x34.3x15.6	inch

Fan details


Impeller blades	4
Impeller type	5
Impeller system	G
Impeller material	PG

Control options

Triac controller	No
Transformer	No
Frequency drive	Yes
Intelligent Fan Drive	No

Characteristics

0.00 in. wg	13359 CFM
0.60 in. wg	10828 CFM

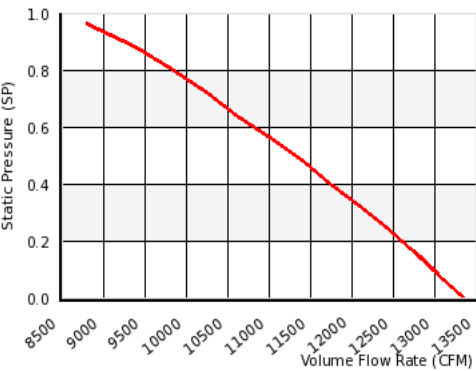


Please note: Picture may deviate from original product

Approval(s)




Wiring diagram - Fan

AB01 - 3 Phase - Star connected - CCW

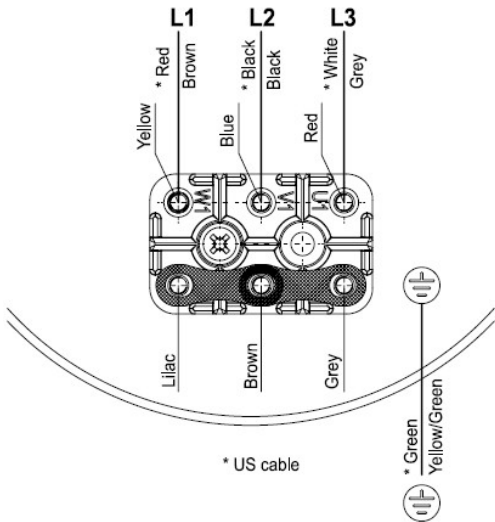

Dimensions

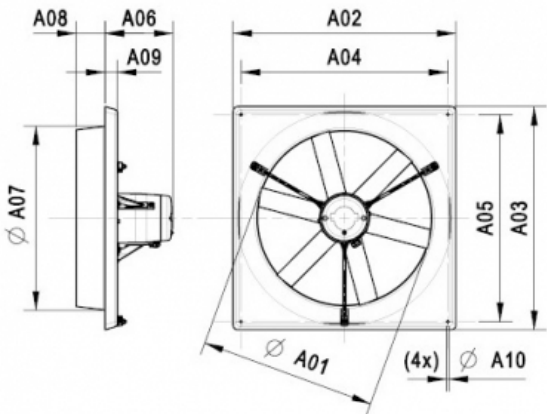

A01	28.0 inch
A02	33.5 inch
A03	33.5 inch
A04	31.1 inch
A05	31.1 inch
A06	9.7 inch
A07	29.1 inch
A08	4.1 inch
A09	1.6 inch
A10	0.4 inch



VOSTERMANS
VENTILATION

Vostermans Ventilation Inc.
Bloomington, IL - U.S.A.
+1 309 827 9798
ventilation@vostermansusa.com
www.vostermansusa.com

AVAILABLE THROUGH

