

COMPONENT LIST, Y1MRTC-KIT


ITEM	CATALOG NO.	QTY.	DESCRIPTION	COPPER WIRE SIZE AND TYPE ACCOMMODATED	STUD SIZE	STUD HOLE SPACING	NO. OF CRIMPS	DIE COLOR	DIE INDEX
1	Y1MRTC	1	HYTOOL™ FULL CYCLE RATCHET HAND TOOL	--	--	--	--	--	--
2	YA2CL2TC38	15	HYLUG™ TERMINAL	2 AWG STR 35mm ² CLASS 2	3/8	1"	2	BROWN	10
3	YA4CL2TC38	15	HYLUG™ TERMINAL	4 AWG STR	3/8	1"	2	GREY	8
4	YA6CL2TC38	15	HYLUG™ TERMINAL	6 AWG STR	3/8	1"	1	BLUE	7
5	YA8CL2TC38	15	HYLUG™ TERMINAL	8 AWG STR 6 SDL 8 WELD 37/24 10mm ² CLASS 2 & 5	3/8	1"	1	RED	49
6	YA2CL2TC14	15	HYLUG™ TERMINAL	2 AWG STR 35mm ² CLASS 2	1/4	5/8"	2	BROWN	10
7	YA4CL2TC14	15	HYLUG™ TERMINAL	4 AWG STR	1/4	5/8"	1	GREY	8
8	YA6CL2TC14	15	HYLUG™ TERMINAL	6 AWG STR	1/4	5/8"	1	BLUE	7
9	YA6CL2TC14E1	15	HYLUG™ TERMINAL	6 AWG STR	1/4	1"	1	BLUE	7
10	YA6CL2TC14E2	15	HYLUG™ TERMINAL	6 AWG STR	1/4	3/4"	1	BLUE	7
11	YA8CL2TC14	15	HYLUG™ TERMINAL	8 AWG STR 6 SDL 8 WELD 37/24 10mm ² CLASS 2 & 5	1/4	5/8"	1	RED	49
12	YAV6CL2TC14FX	15	HYLUG™ TERMINAL	6 WELD 61/24 16mm ² CLASS 2 & 5	1/4	5/8"	1	BLUE	7
13	YAV6CL2TC14E2FX	15	HYLUG™ TERMINAL	6 AWG STR 6 WELD 61/24 16mm ² CLASS 2 & 5	1/4	3/4"	1	BLUE	7
14	YA2C2TC38	15	HYLUG™ TERMINAL	2 AWG STR 35mm ² CLASS 2	3/8	1"	4	BROWN	10
15	YA3C2TC38	15	HYLUG™ TERMINAL	3 AWG STR 2 SDL 50mm ² CLASS 2	3/8	1"	4	WHITE	9
16	YA6C2TC38	15	HYLUG™ TERMINAL	6 AWG STR	3/8	1"	2	BLUE	7
17	YC4L12	15	COPPER C-TAP	6 STR RUN TO 6-8 STR TAP 5-4 STR RUN TO 12-8 STR TAP	--	--	2	BROWN	10

REV.	DATE	DESCRIPTION	ECO	BY	C'K'D.
A	02/12/02	DRAWING RELEASED.	7118	DB	GS

KIT IDENTIFICATION LABEL OUTLINES KIT CONTENTS AND PROVIDES CONNECTOR INSTALLATION INFORMATION.


FOAM INSERT CONTAINS Y1MRTC HYTOOL™ AND HELPS TO PROTECT TOOL FROM IMPACT IF CASE IS DROPPED.

VIEW OF INSIDE COVER WHEN OPENED

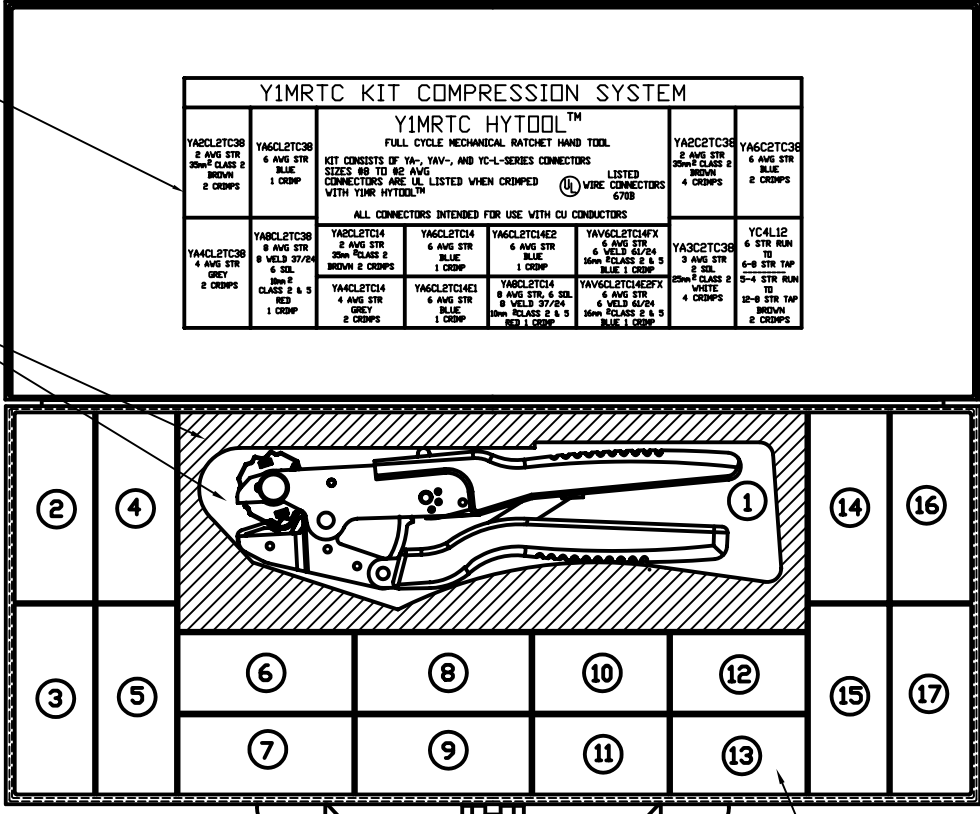

Y1MRTC KIT COMPRESSION SYSTEM			
Y1MRTC HYTOOL™ FULL CYCLE MECHANICAL RATCHET HAND TOOL KIT CONSISTS OF YA-, YAV-, AND YC-L-SERIES CONNECTORS SIZES 8B TO 8E AWG CONNECTORS ARE UL LISTED WHEN CRIMPED WITH YOUR HYTOOL™			
YA2CL2TC38 2 AWG STR 35mm ² CLASS 2 BROWN 2 CRIMPS	YA6CL2TC38 6 AWG STR BLUE 1 CRIMP	YA2C2TC38 2 AWG STR 35mm ² CLASS 2 BROWN 4 CRIMPS	YA6C2TC38 6 AWG STR BLUE 2 CRIMPS
ALL CONNECTORS INTENDED FOR USE WITH CU CONDUCTORS			
YA4CL2TC38 4 AWG STR GREY 2 CRIMPS	YA8CL2TC38 8 AWG STR 6 WELD 37/24 10mm ² CLASS 2 & 5 RED 1 CRIMP	YA2CL2TC14 2 AWG STR 35mm ² CLASS 2 BROWN 2 CRIMPS	YA4CL2TC14 4 AWG STR GREY 1 CRIMP
YA6CL2TC14 6 AWG STR BLUE 1 CRIMP	YA8CL2TC14 8 AWG STR 6 WELD 37/24 10mm ² CLASS 2 & 5 RED 1 CRIMP	YAV6CL2TC14FX 6 WELD 61/24 16mm ² CLASS 2 & 5 BLUE 1 CRIMP	YAV6CL2TC14E2FX 6 AWG STR 6 WELD 61/24 16mm ² CLASS 2 & 5 BLUE 1 CRIMP
YC4L12 6 STR RUN TO 6-8 STR TAP 5-4 STR RUN TO 12-8 STR TAP BROWN 2 CRIMPS			

HEAVY GAUGE STEEL COVER/BODY.

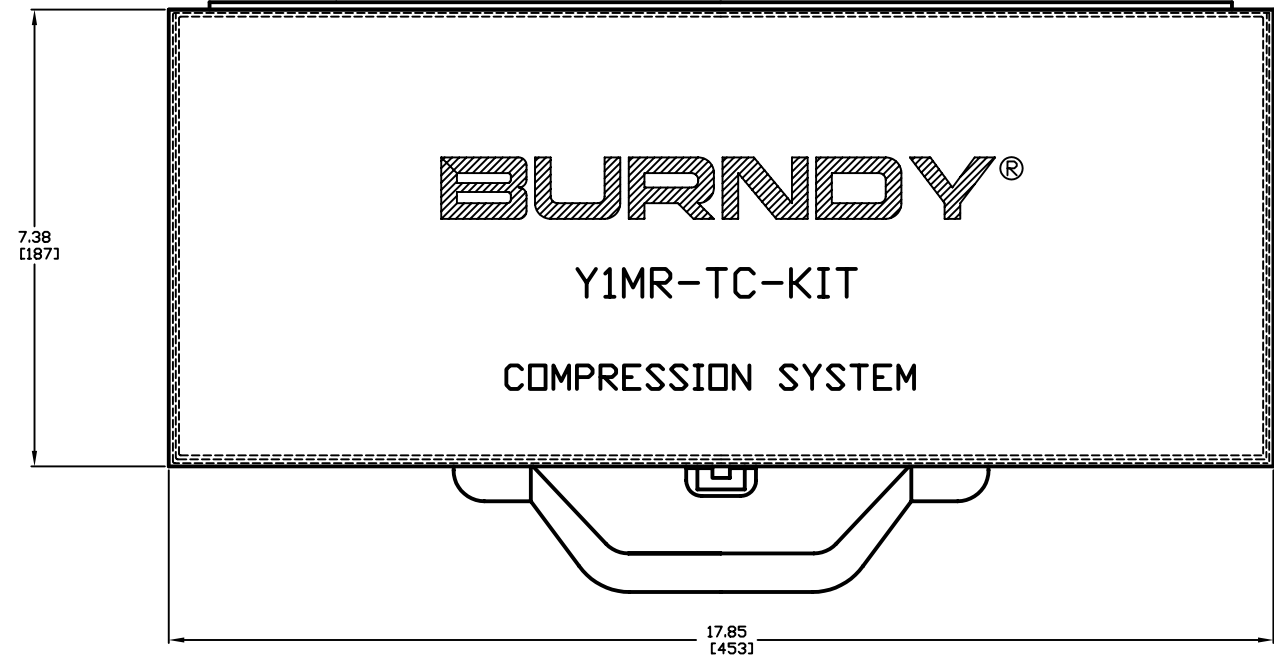

INDIVIDUAL COMPARTMENTS HOLD A VARIETY OF CONNECTORS, COVER PROHIBITS SPILLAGE OF CONNECTOR CONTENTS WHEN CLOSED.

RUGGED CLASP AND HANDLE PROVIDE LONG CARRY CASE LIFE.

NOTES:

- DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE NOTED, AND ARE FOR REFERENCE ONLY.
- DIE INDEX 10 (BROWN DIE) & DIE INDEX 11 (GREEN DIE) DIE USE THE SAME DIE WHEEL CRIMP GROOVE AND WILL EMBOSS THE CONNECTOR WITH BOTH INDEX NUMBERS.

TO ORDER BURNDY® PRODUCTS CALL
 UNITED STATES:
 1-800-346-4175 (LONDONDERRY, NH)
 CANADA:
 1-800-361-6975 (QUEBEC)
 1-800-387-6487 (ALL OTHER PROVINCES)
 FOR PRODUCT INFO: <http://www.burndy.com>

Y1MR-TC-KIT COMPRESSION SYSTEM	
ITEM NO:	N/A
CAT NO:	Y1MR-TC-KIT
SCALE:	1/1
DRAWN BY:	D BOISVERT 11/26/01
CHECKER:	G SCHRADER 2/15/02
DSN APPVL:	G SCHRADER 02/20/02
MFG APPVL:	A ZWIT 02/20/02
QC APPVL:	J BRODEUR 02/20/02
MKT APPVL:	--
PROJ FAM:	--
PROJECT #:	--
DOCUMENT TYPE:	Sales
REL LEVEL:	AutoCAD
DRAWING NO	SD214076-01
REV	A
SIZE	D
SHEET	1 OF 1

