

Straight Blade Devices

Miscellaneous and Combination Receptacles

2 Pole, 3 Wire Grounding



HBL5236



HBL5235



 


 
 
 

 



Miscellaneous Receptacles


Description	Catalog Number
Receptacle, display type, brown phenolic with .060 in. brass plate and blank flush plug.	HBL5236
Replacement receptacle for HBL5236.	HBL5236M2
Replacement threaded plug for HBL5236.	HBL5236PLUG*
Receptacle, wooden floors, brown phenolic with .060 in. brass plate, blank flush plug and box.	HBL6236
Receptacle, clock hanger, white with stainless steel plate.	HBL5235




15A 125V
NEMA 5-15R
UL CSA
0.5 HP

Special Combination Duplex Receptacles

Description	Catalog Number
15A, 125V  Brown RTP, 1 feed, 1 return, back/side wired	HBL4792
15A, 125V  Brown RTP, 2 feeds, 1 return, side wired	HBL4794
15A, 125V  Brown RTP, 2 feeds, 2 returns, side wired	HBL4795
15A, 250V  Brown nylon face, 2 circuit, back and side wired	HBL5292
15A, 125V  Ivory nylon face, 2 circuit, back and side wired	HBL5292I
20A, 250V  Brown nylon face, 2 circuit, back and side wired	HBL5492
20A, 125V  Ivory nylon face, 2 circuit, back and side wired	HBL5492I
15A, 125V  Brown RTP, 2 feeds, 1 return, common ground	HBL7371
10A, 250V 15A, 125V  Brown nylon, side and back wired	HBL5392
20A, 125V  Brown nylon, side and back wired	
20A, 125V  <i>Note: This device will only accept 20A grounding plugs.</i>	

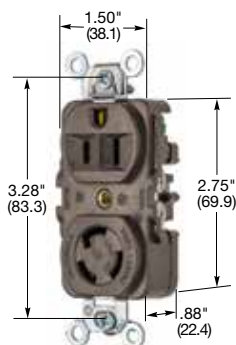

HBL4792

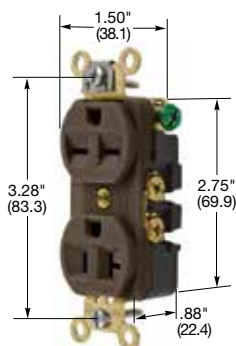

HBL5292

Note: RTP is an abbreviation for reinforced thermoplastic polyester.

**Not UL Listed or CSA certified.*

See page A-47 for accessories.

Dimensions in Inches (mm)