



**MCR
SAFETY**

9371T

Cut Protection Specification Sheet

PRODUCT DESCRIPTION:

When the job calls for protection from cuts and scrapes Kevlar® sleeves step up. All our 100% Kevlar® sleeves have a ANSI cut score of 3 and are constructed of Certified DuPont™ Kevlar® Brand Fiber. The 9371T is a 10 inch Kevlar® sleeve with thumb slot.

FEATURES:

- Made with 100% Kevlar® Brand Fibers
- Made with FDA accepted materials
- 10 inches in length
- Thumb Slot


APPLICATIONS:

Manufacturing, Food service, Glass handling, HVAC, Warehousing, Agriculture, Automotive, Carpentry, Construction, Demolition, Furniture industry, Landscaping, Mechanics



TECHNICAL DATA FOR: 9371T

Material Group	Strings	Overall Length	10 in.
Product Type	Cut Protection	ANSI Cut	ANSI Cut A3
Gauge	7 Gauge	ANSI Abrasion	ANSI Abrasion 2
Material	Kevlar	ANSI Contact Heat	Level 2 (Applications less than 284 degrees F)

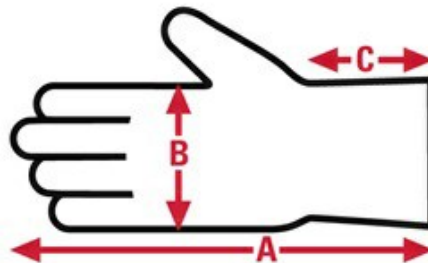

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved



MCR
SAFETY

9371T

**Cut Protection
Specification Sheet**

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
9371T	N/A	0	0	N/A	9.000 lb.	0.060

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved