




LIQUIDTIGHT UF CONNECTORS

Underground Feeder, Liquidtight - Steel
N/A

B79

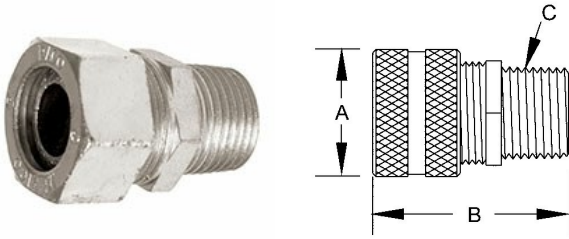

Catalog #: 2462

APPLICATIONS

For use with underground feeder (UF) cable to provide a liquidtight connection to meters and enclosures
N/A

PRODUCT FEATURES

Rugged metallic construction will last the life of the installation

UL LISTED

Standard 514B

CSA

C22.2 No. 18

GENERAL PRODUCT INFORMATION

Trade Size:	1/2 in.
Min Grommet Opening:	.225 in.
Max Grommet Opening:	.425 in.
UF Wire Size:	2#14; 2#12

DRAWING DIMENSIONS

Dimension A:	1.25 in.
Dimension B:	1.75 in.
Dimension C:	1/2 in. - 14

PACKAGING

Package Type:	Carton
Std. Pkg.:	25
Ship Carton Qty.:	100
Product UPC-A Labeled:	No
Weight (Lbs. Per/C):	16.60
Ship Carton Length (in.):	9.88
Ship Carton Width (in.):	7.38
Ship Carton Height (in.):	9.00
Ctn Weight (Lbs.):	16.60
UPC Number:	050169024621
I2of5:	50050169024626