




## MULTI GANG NON-METALLIC CABLE BOXES - WITH CAPTIVE NAILS

Two-gang with Captive Nails for Wood Studs - For Nonmetallic Sheathed Cable  
2-29/32 in. Deep, Nails

A76

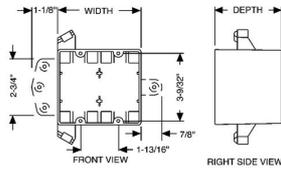

Catalog #: 7835RAC

### APPLICATIONS

RACO® Nonmetallic cable boxes are used in branch circuit wiring to splice wires  
Accommodates wiring devices such as switches and receptacles  
Provide excellent protection for wiring system or devices

### PRODUCT FEATURES

RACO® Nonmetallic cable boxes provide the installer with a cost alternative that is lightweight and easy to install  
Self-clamping wire entry clamps  
Positioning tabs for fast accurate mounting on studs or joists  
Oversized nail support that resists hammer impact and prevents box deformation

### UL LISTED

File E 195963

### COMPLIANCES

Boxes are listed for Applications (Electrical Codes), UL Green Book  
Boxes are listed for mechanical properties, including the 2-hour Fire Rating (except 7645RAC), (building codes) UL Orange Book  
Federal Manufacturer's number 28488

### FIRE RESISTANCE

2-hour fire rating, UL Orange Book

### US PATENTS

4,605,816; 4,580,689; 4,666,055

### OTHER PATENTS

Canada 1,233,900; 1,237,515; 1,260,599

### GENERAL PRODUCT INFORMATION

Wiring System: Nonmetallic Sheathed Cable  
Color: Gray

### CONFIGURATION

Cable Knockouts(s): ---  
Cable Clamps: 8

### DRAWING DIMENSIONS

Dimension A: 2-29/32 in.

### PRODUCT MEASUREMENTS

Depth: 2-29/32 in.  
Cubic Inches (cm3): 32.5 (532.5)  
Wt. Ea. (Lbs.): 0.375  
Product Length (in.): 2.91  
Product Width (in.): 6.45  
Product Height (in.): 4.00

### PACKAGING

Minimum Pack Qty.: 15  
Std. Pkg.: 15  
Product UPC-A Labeled: Yes  
Weight (Lbs. Per/C): 37.50  
Ship Carton Length (in.): 14.00  
Ship Carton Width (in.): 11.00  
Ship Carton Height (in.): 12.00  
Ctn Weight (Lbs.): 5.63

Pallet Qty:  
UPC Number:  
I2of5:

720  
050169978351  
50050169978356