

Hose and Cable Protection Systems

FloorTrak® Floor Cable Cover

For Pedestrian Traffic in Office and Public Areas

- Flexible and rigid PVC material
- Protects and reduces trip hazards
- Available in four different sizes and five PVC colors to blend with the various decors
- Withstands temperatures of 0°F to +120°F (-18°C to +49°C)



FloorTrak® 2*

| Color | Length Feet (meters) | Catalog Number |
|--------|-------------------------|-------------------|
| Black | 10.0' (3.05) | FT2BK10 |
| Brown | 10.0' (3.05) | FT2BR10 |
| Beige | 10.0' (3.05) | FT2BG10 |
| Gray | 10.0' (3.05) | FT2GY10 |
| Yellow | 10.0' (3.05) | FT2Y10 |



FloorTrak® 4

| Color | Length Feet (meters) | Catalog Number |
|--------|-------------------------|-------------------|
| Black | 5.0' (1.52) | FT4BK5 |
| Black | 25.0' (7.62) | FT4BK25 |
| Gray | 25.0' (7.62) | FT4GY25 |
| Yellow | 5.0' (1.52) | FT4Y5 |
| Yellow | 25.0' (7.62) | FT4Y25 |



FloorTrak® 3*

| Color | Length Feet (meters) | Catalog Number |
|--------|-------------------------|-------------------|
| Black | 5.0' (1.52) | FT3BK5 |
| Black | 25.0' (7.62) | FT3BK25 |
| Brown | 5.0' (1.52) | FT3BR5 |
| Brown | 25.0' (7.62) | FT3BR25 |
| Beige | 5.0' (1.52) | FT3BG5 |
| Beige | 25.0' (7.62) | FT3BG25 |
| Gray | 5.0' (1.52) | FT3GY5 |
| Gray | 25.0' (7.62) | FT3GY25 |
| Yellow | 5.0' (1.52) | FT3Y5 |
| Yellow | 25.0' (7.62) | FT3Y25 |



FloorTrak® 10 (Heavy Duty)

| Color | Length Feet (meters) | Catalog Number |
|--------|-------------------------|-------------------|
| Black | 3.0' (.914) | FT10BK3 |
| Black | 5.0' (1.52) | FT10BK5 |
| Yellow | 3.0' (.914) | FT10Y3 |
| Yellow | 5.0' (1.52) | FT10Y5 |



Accessories


| Description | Catalog Number |
|---|----------------|
| 1" Wide, 75' Roll Double-Sided Adhesive Tape. | FTT1 |
| 2" Wide, 75' Roll Double-Sided Adhesive Tape. | FTT2 |



Note: *ADA Compliant Section 4.5.2.

Dimensions

| FloorTrak® | FT2 in. (mm) | FT3 in. (mm) | FT4 in. (mm) | FT10 (Heavy Duty) in. (mm) |
|---------------------|-------------------------------|--------------------------------|---------------------------------|----------------------------------|
| Width (A) | 2.75" (69.9) | 3.00" (76.2) | 3.25" (82.6) | 5.6" (142.24) |
| Height (B) | .53" (13.5) | .75" (19.1) | 1.10" (27.9) | 1.7" (43.18) |
| Center Hole (Cx Dx) | .60" x .31" (15.2) x (7.9) | .75" x .50" (19.1) x (12.7) | 1.21" x .75" (30.7) x (19.1) | 1.81" x 1.25" (45.98 x 31.75) |

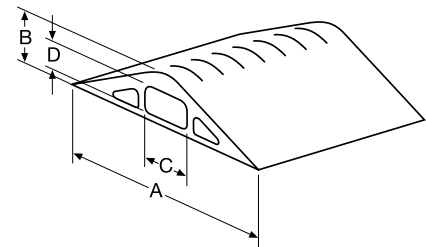

Specifications

| | |
|-----------------------|---------------------------------|
| Material | Rigid PVC. |
| Operating Temperature | 0°F to +120°F (-18°C to +49°C). |

Dimensions in Inches (mm)