


T&B Portable Cord Fittings

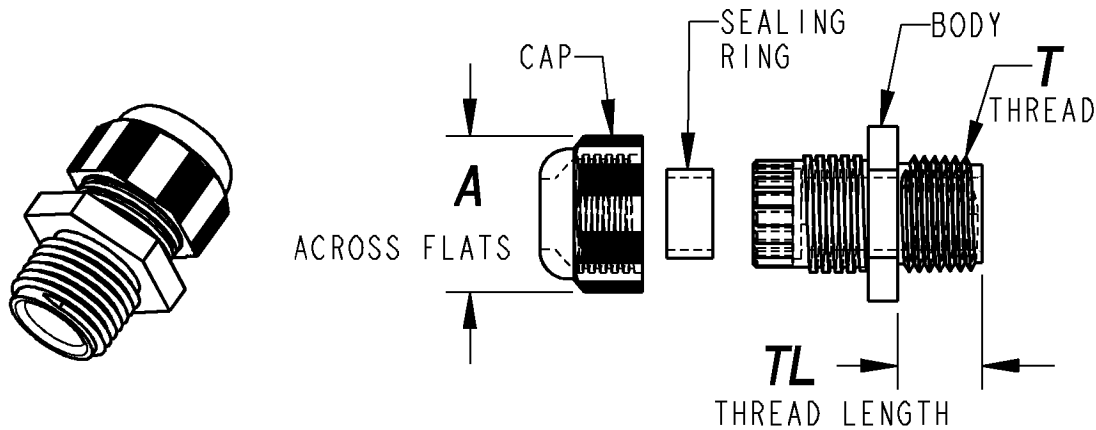

MATERIAL: BODY AND CAP- POLYANIDE 6
 SEALING RING: NEOPRENE
 COLOR: GRAY (RAL 7001)
 BLACK (RAL 9005)
 PROTECTION CLASS: IP 68, 5 BAR
 TEMPERATURE RANGE: -30°C TO 80°C PERMANENT
 OPERATING TEMPERATURE: UP TO +150°C INTERMITTENT

CATALOG NUMBER	SIZE	COLOR	NUMBER HOLES	CLAMPING RANGE		ACROSS FLATS	THREAD	THREAD LENGTH
				MAXIMUM	MINIMUM			
CC-NPT34-G4	3/4"	GRAY	4	.290	.230	1.299	3/4-14 NPT	.590
CC-NPT34-G3	3/4"	GRAY	3	.290	.230	1.299	3/4-14 NPT	.590
CC-NPT34-G2	3/4"	GRAY	2	.290	.230	1.299	3/4-14 NPT	.590
CC-NPT12-G3	1/2"	GRAY	3	.250	.190	1.063	1/2-14 NPT	.590
CC-NPT12-G2	1/2"	GRAY	2	.250	.190	1.063	1/2-14 NPT	.590

GENERAL NOTES

1. DIMENSIONS IN PARENTHESES () ARE IN METRIC UNITS.
2. DIMENSIONS IN BRACKETS [] ARE IN METRIC UNITS.

REVISIONS

SEE ERN () FOR APPROVAL SIGNATURES

PROJECT NO:

Thomas & Betts
www.tnb.com

DESCRIPTION:

NONMETALLIC MULTI-HOLE CABLE GLAND

ORIGINAL PROJECT NO / (ERN NO)

RM401858/ (2008553)

SHEET NO:

1 OF 1

REV. NO:

-

DRAWING NO:

WSD-000375

THIS DRAWING IS INTENDED FOR DESCRIPTIVE PURPOSES ONLY. AND THE RIGHT IS RESERVED TO DEVIATE FROM ANY OF THE DETAILS SHOWN HEREON.

©2007 Thomas & Betts - Proprietary. All Rights Reserved