



# Hammer-On Flange Clip, Side Mount – 4H24

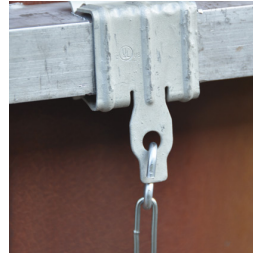

- Provides an attachment for wire, S-hooks, chain, nVent CADDY Speed Link or other assemblies to flanges and profiles
- Fits most beams
- Installs with just a hammer

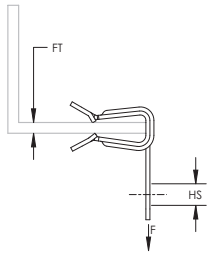

Part Number	4H24
Material	Spring Steel
Finish	nVent CADDY Armour
Flange Thickness (FT)	1/8" – 1/4"
Hole Size (HS)	1/4"
Static Load (F)	200 lb
Certifications	CE, 4H, EM, EBC cULus ITB
Standard Packaging Quantity	100 pc
UPC	78285611100
EAN-13	8711893700244

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC.

#### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.erico.com](http://www.erico.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

© 2021 nVent All rights reserved

nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.

All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.

