



IG4700A

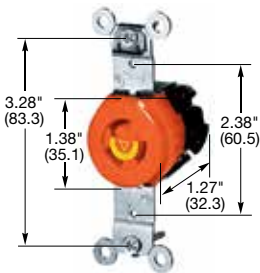

IG4710

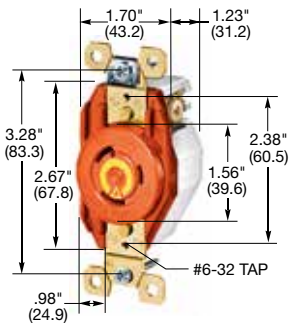

IG2310

15A, 125V and 250V Back and Side Wired



15A 125V
NEMA L5-15R
UL/CSA



15A 250V
NEMA L6-15R
UL/CSA

Description	Poles/Wires	Color	Catalog Number	Catalog Number
Flush, RTP face, duplex.	2 pole, 3 wire	Orange	IG4700A*	IG4550A*
Flush, RTP face, single.	2 pole, 3 wire	Orange	IG4710	IG4560

*Note: RTP is an abbreviation for reinforced thermoplastic polyester.
Supplied with break-off tabs for split circuit wiring.

20A, 125V, 250V and 480V AC Back and Side Wired



20A 125V
NEMA L5-20R
UL/CSA
1 HP



20A 250V
NEMA L6-20R
UL/CSA
2 HP



20A 480V AC
NEMA L8-20R
UL/CSA
3 HP

Description	Poles/Wires	Color	Catalog Number	Catalog Number	Catalog Number
Flush, nylon face, single.	2 pole, 3 wire	Orange	IG2310	IG2320	IG2340

30A, 125V and 250V Back and Side Wired



30A 125V
NEMA L5-30R
UL/CSA
2 HP



30A 250V
NEMA L6-30R
UL/CSA
2 HP

Description	Poles/Wires	Color	Catalog Number	Catalog Number
Flush, nylon face, single.	2 pole, 3 wire	Orange	IG2610	IG2620

20A, 125V/250V and 3Ø 250V AC Back and Side Wired



20A 125/250V AC
NEMA L14-20R
UL/CSA
2 (1) HP



20A 3Ø 250V AC
NEMA L15-20R
UL/CSA
3 HP

Description	Poles/Wires	Color	Catalog Number	Catalog Number
Flush, nylon face, single.	3 pole, 4 wire	Orange	IG2410	IG2420

30A, 125V/250V and 3Ø 250V AC Back and Side Wired



30A 125/250V AC
NEMA L14-30R
UL/CSA
2 (2) HP



30A 3Ø 250V AC
NEMA L15-30R
UL/CSA
3 HP

Description	Poles/Wires	Color	Catalog Number	Catalog Number
Flush, nylon face, single.	3 pole, 4 wire	Orange	IG2710	IG2720

20A and 30A, 3ØY 120/208V AC Back and Side Wired



20A 3ØY
120/208V AC
NEMA L21-20R
UL/CSA
2 HP



30A 3ØY
120/208V AC
NEMA L21-30R
UL/CSA
3 HP

Description	Poles/Wires	Color	Catalog Number	Catalog Number
Flush, nylon face, single.	4 pole, 5 wire	Orange	IG2510	IG2810

Dimensions in Inches (mm)