

TECHNICAL DATA SHEET


Part#: 2642

Pliers - 2 Star Small Flat Nose - SS

Ideal for straightening wires or component leads.

The 2642 small flat nose plier has an overall length of 4.75". It is made of stainless steel and features dual leaf springs for smooth action. The Anti-Static grips are soft cushioned foam and have a surface resistivity of 10^{10} ohms/sq.

- Precision Level ★★
- Material SS (AISI 440)
- Surface Resistivity 10^{10} ohms/sq
- Shape Flat Nose
- Tip Size .025" x .1" (.625mm x 2.5mm)
- Tip Angle
- Tip Length .9"(22.5mm)
- Body Width
- Body Height
- OAL 4.75" (118.75mm)
- Weight (OZ) 3.5
- UPC 662847008511
- Schedule B 8203.20.60.30
- ECCN EAR99
- UNSPSC Code 27112126
- Country of Origin Pakistan
- Group Small Nose

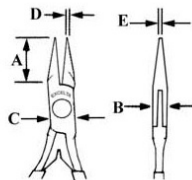

2642 Flat Nose Pliers
Smooth Jaw

- A= .906"
- B= .235"
- C= .375"
- D= .020"
- E= .095"