


TECHNICAL DATA SHEET

Part#: 2829

Pliers - 2 Star Medium 60° Bent Nose - SS
Offers excellent visibility and accessibility

The 2829 medium 60° bent nose plier has an overall length is 5.75". It is made of stainless steel and feature dual leaf springs for smooth action. It features a ergonomically molded antimicrobial Anti-Static grip (10¹⁰ ohms/sq surface resistivity) with dual leaf springs.

- Precision Level ★★
- Material SS (AISI 440)
- Surface Resistivity 10¹⁰ ohms/sq
- Shape Bent Nose
- Tip Size .05" x .085" (1.25mm x 2.125mm)
- Tip Angle 60°
- Tip Length 1.3"(32.5mm)
- Body Width
- Body Height
- OAL 5.75" (143.75mm)
- Weight (OZ) 4
- UPC 662847008627
- Schedule B 8203.20.60.30
- ECCN EAR99
- UNSPSC Code 27112128
- Country of Origin Pakistan
- Group Medium Nose

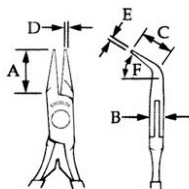

2629 Bent Nose Pliers
Smooth Jaw

- A= .985"
- B= .257"
- C= .200"
- D= .015"
- E= .040"
- F= 45 degrees

