

## STAINLESS STEEL RIGHT ANGLE CLAMP




### Features:

- Manufactured in type 316 stainless steel for increased corrosion resistance
- Polished with standard "brite" finish to increase corrosion resistance and aesthetic appearance
- Type 316 stainless steel hex nuts included
- No package qty. required

### Certifications and Compliances:

- Calbrite stainless steel Right Angle Clamps are fabricated to UL standards

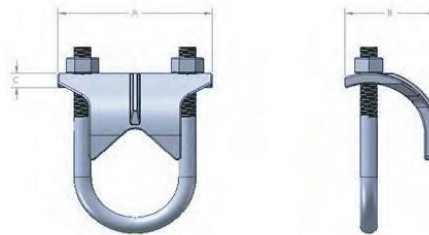

### Applications:

Designed to fit stainless rigid, IMC and EMT conduit. Can also be used for PVC-coated conduit. Calbrite Right Angle Clamps are used to mount conduit to the flange of a structural member without drilling holes. Cast in 316 stainless steel, these clamps provide both excellent strength and corrosion resistance.

### Industries Commonly Served:

- Food & Beverage Production & Distribution
- Chemical Plants
- Water & Wastewater Treatment
- Pharmaceuticals & Cosmetics
- Refining & Extraction Sites
- Petrochemical
- Pulp & Paper Mills
- Marine & Coastal Facilities

Part Number	Trade Size	A	B	C	Weight (each) Per lb.
S60500RA00	1/2"	2.000"	1.600"	.245"	0.32
S60700RA00	3/4"	2.070"	1.600"	.255"	0.35
S61000RA00	1"	2.590"	1.600"	.255"	0.45
S61200RA00	1-1/4"	2.840"	1.600"	.270"	0.50
S61500RA00	1-1/2"	3.330"	1.600"	.270"	0.60
S62000RA00	2"	3.850"	1.690"	.310"	0.95
S62500RA00	2-1/2"	4.580"	1.800"	.330"	1.25
S63000RA00	3"	5.220"	1.850"	.330"	1.45
S64000RA00	4"	6.180"	1.850"	.330"	1.70

*All dimensions are for informational purposes only \*Tolerances +/- 5%*