

STAINLESS STEEL "MINI" HANGERS




Features:

- Manufactured in type 316 stainless steel to meet any stringent sanitary condition
- Polished with standard "brite" finish to increase corrosion resistance and aesthetic appearance
- Designed for use with stainless rigid, stainless IMC, galvanized and aluminum conduit
- Type 316 stainless steel nut and bolt (carriage) included
- No package qty. required

Certifications and Compliances:

- Calbrite stainless steel One Hole Straps are fabricated to meet UL standards

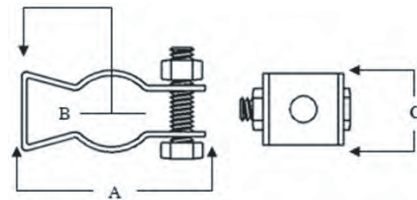

Applications:

Heavy duty type 316 stainless steel conduit hangers are great for securing and mounting conduit, tubing and cable in corrosive environments.

Industries Commonly Served:

- Food & Beverage Production & Distribution
- Chemical Plants
- Water & Wastewater Treatment
- Pharmaceuticals & Cosmetics
- Refining & Extraction Sites
- Petrochemical
- Pulp & Paper Mills
- Marine & Coastal Facilities

Part Number	Trade Size	A	B	C	Nut & bolt size / Bolt hole size	Weight (each) Per lb.
S60500MH00	1/2"	1.90"	7/8"	0.75"	1/4"	0.06
S60700MH00	3/4"	2.35"	15/16"	.870"	1/4"	0.08
S61000MH00	1"	2.63"	1-1/8"	.870"	1/4"	0.10
S61200MH00	1-1/4"	3.30"	1-3/8"	.870"	1/4"	0.12
S61500MH00	1-1/2"	3.38"	1-7/16"	1.25"	1/4"	0.20
S62000MH00	2"	4.15"	2"	1.25"	1/4"	0.22
S62500MH00	2-1/2"	4.60"	2-1/16"	1.25"	1/4"	0.26
S63000MH00	3"	5.45"	2-11/16"	1.25"	1/4"	0.30
S64000MH00	4"	6.70"	3-3/16"	1.25"	1/4"	0.36

*All dimensions are for informational purposes only *Tolerances +/- 5%*