

STAINLESS STEEL SPLIT RING CLAMPS

Features:

- Manufactured in type 316 stainless steel to meet any stringent sanitary condition
- Polished with standard "brite" finish to increase corrosion resistance and aesthetic appearance
- Designed for use with stainless steel Rigid / IMC, aluminum and galvanized conduit
- Includes two type 316 stainless steel bolts
- No package qty. required

Certifications and Compliances:



- Complies with Manufacturers' Standardization Society MSS SP-58 & SP-69
- Meets Federal Specifications WW-H-171

Applications:

Calbrite's stainless steel Split Ring Clamps are designed for mounting and securing conduit, horizontally or vertically, away from the wall or device in wash-down or corrosive environments when used with Calbrite's Mounting Plates and Extensions.

Industries Commonly Served:

- Food & Beverage Production & Distribution
- Chemical Plants
- Water & Wastewater Treatment
- Pharmaceuticals & Cosmetics
- Refining & Extraction Sites
- Petrochemical
- Pulp & Paper Mills

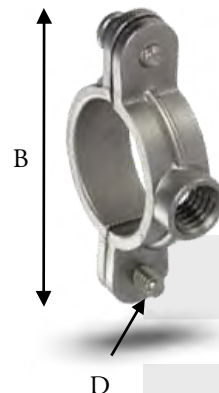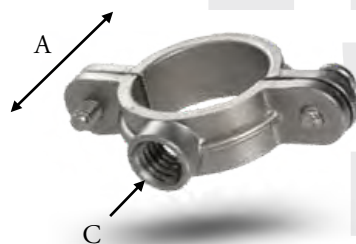

Part Number	Trade Size	A (Height)	B (Length)	C (Female Thread)	D (Bolt Size)	Thickness	Weight (ea) per lb.
S60500SP00	1/2"	1.16"	2.18"	.375"	#10 x 1/2"	.125"	0.09
S60700SP00	3/4"	1.41"	2.50"	.375"	#10 x 1/2"	.125"	0.11
S61000SP00	1"	1.75"	2.70"	.375"	#10 x 1/2"	.135"	0.14
S61200SP00	1-1/4"	2.03"	3.23"	.375"	#10 x 1/2"	.140"	0.16
S61500SP00	1-1/2"	2.42"	3.50"	.375"	#10 x 1/2"	.150"	0.20
S62000SP00	2"	2.87"	3.92"	.375"	#10 x 1/2"	.150"	0.23
S62500SP00	2-1/2"	3.65"	5.00"	.500"	1/4"-20	.160"	0.50
S63000SP00	3"	4.25"	5.76"	.500"	1/4"-20	.210"	0.75
S64000SP00	4"	5.30"	6.83"	.500"	1/4"-20	.250"	1.13

*All dimensions are for informational purposes only *Tolerances +/- 5%*