

## STAINLESS STEEL EMT COMPRESSION UNIONS (COUPLINGS)



### Features:

- Manufactured in type 316 stainless steel for increased corrosion resistance
- Polished with standard "brite" finish to increase corrosion resistance and aesthetic appearance
- Designed for use with stainless EMT
- Addition of stainless and plastic ferrules assures weatherproof seal
- Connectors assembled with ferrules, no separate pieces to purchase or stock
- No package qty. required

### Certifications and Compliances:


- Calbrite stainless steel EMT fittings are fabricated to meet UL standards
- NEMA 4X approved

### Material:

- Body: 316SS
- Stainless Ferrule: 316SS
- Red Ferrule: Nylon

### Applications:

Used to join two lengths of stainless EMT.

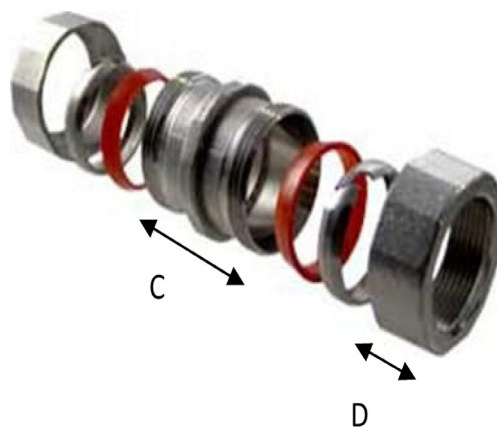

### Industries Commonly Served:

- Food & Beverage Production
- Marine & Coastal Facilities
- Chemical Plants
- Water & Wastewater Treatment
- Pharmaceuticals & Cosmetics
- Refining & Extraction Sites
- Petrochemical Operations
- Pulp & Paper Mills
- Along with other corrosive environments

Part Number	Size	A	B	C	D	I.D.	Weight each per lb
S20500CC00	1/2"	2.075"	1.050"	1.350"	0.540"	0.706"	0.16
S20700CC00	3/4"	2.100"	1.250"	1.350"	0.540"	0.922"	0.20
S21000CC00	1"	2.200"	1.550"	1.500"	0.570"	1.163"	0.30
S21200CC00	1-1/4"	2.500"	1.930"	1.770"	0.570"	1.510"	0.48
S21500CC00	1-1/2"	2.600"	2.250"	1.900"	0.600"	1.740"	0.60
S22000CC00	2"	2.770"	2.750"	2.125"	0.650"	2.200"	0.86

All dimensions are for informational purposes only \*Tolerances +/- 5%