

Hubbellock® Devices
30A, 600V AC, 20A, 250V DC, 4 Pole, 5 Wire
Grounding

Hubbellock® Receptacle

Features

- Spring loaded safety shutter contains arcing when mating or un-mating devices under load
- Spring loaded safety shutter automatically ejects the plug eliminating contact teasing
- Box terminals in conjunction with screws with pressure pads provide maximum termination strength and dependability
- Metallic housing provides protection from damage in harsh environments

Ordering Information

Description	Device Color	UPC	Catalog Number
Black phenolic interior, aluminum housing, blue finish.	Blue	783585017464	HBL25403

Listings

Listed to UL Standard
Certified to CSA Standard


Specifications

Housing	Cast aluminum
Receptacle Interior	Thermoset
Contacts	Brass
Terminal Screws	Zinc plated steel

Performance

Electrical	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	2,000V minimum
Mechanical	
Terminal Accommodation	#10 AWG - #6 AWG solid or stranded copper wire only.
Terminal Identification	Terminals identified in accordance with UL 498
Environmental	
Flammability	UL 94 V0 for Receptacles and Inlets.HB or better for Plugs and Connectors
Moisture Resistance	IP30 Suitability
Operating Temperatures	Maximum Continuous 75°C; Minimum -40°C (w/o impact)

HUBBELL

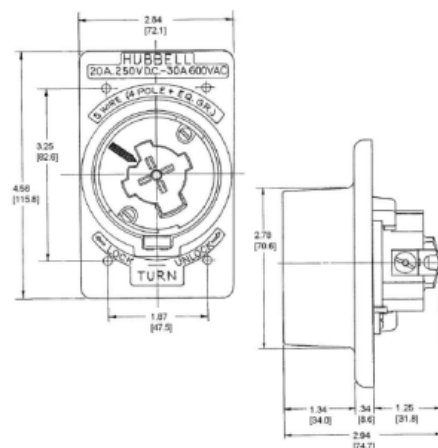

Accessories

Plug	HBL25415B
------	-----------

Resources

Customer Use Drawing
eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

