

20 Amp, 250 Volts
2 Pole, 2 Wire, Non-Grounding




20A 250V
NEMA L2-20P
2 HP

Plugs

Description	Cord Dia.	Catalog Number
Black and white nylon, polarized, multiple drive screws.	.220"-.720" (5.6-18.3)	HBL7102C

Note: See page B-53 for accessories.

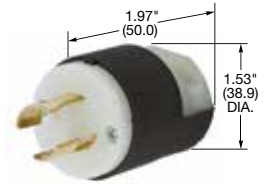


HBL7102C

Flanged Inlets

Description	Catalog Number
Nylon casing, back wired, polarized, multiple drive screws.	HBL8815C

Note: See page B-52 for accessories.

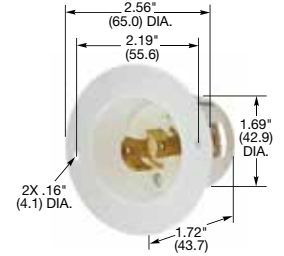

HBL8815C



20A 250V
NEMA L2-20R
2 HP

Connector Bodies

Description	Cord Dia.	Catalog Number
Black and white nylon, multiple drive screws.	.220"-.720" (5.6-18.3)	HBL7101C

Note: See page B-53 for accessories.




HBL7101C

Receptacles

Description	Catalog Number
Single, black phenolic.	HBL7210B
Single, mounted on 4" (101.6) round box cover, black phenolic.	HBL7217B

Note: See pages B-52 and B-53 for accessories.

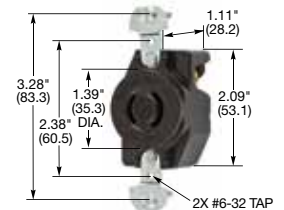

HBL7210B


Flanged Receptacles

Description	Catalog Number
Insulgrip nylon casing, back wired, multiple drive screws.	HBL8809C
Metal flange, stainless steel casing, black phenolic, exposed terminals.	HBL3226

Note: See pages B-52 and B-53 for accessories.
 Only receptacles and plugs are HP rated.
 HP ratings are AC only.



HBL8809C

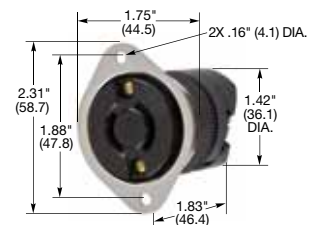

HBL3226

Dimensions in Inches (mm)