

Twist-Lock® Devices
 20A, 277V AC, 2 Pole, 3 Wire Grounding
 Valise® Plug

HUBBELL

Features

- Powerful cord grip prevents conductor slippage and strain on wiring terminals
- Totally insulated impact and crush resistant nylon body
- Unique patented clamp type terminals provide a superior electrical connection by bundling the conductor strands when clamps are tightened

Ordering Information

Description	Cord Diameter	UPC	Catalog Number
Yellow nylon.	.325"-.720" (8.26-18.3)	783585235684	HBL2331VY

Listings

Listed to UL 498
 Fed.Spec. W-C-596
 Certified to CSA C22.2 No.42

Specifications

Housing	Yellow nylon
Blades	Brass
Terminal Screws	#8 - 32 Steel (Philips / Slotted / Robertson)
Terminal Clamps	Steel - Nickel plated
Clamp Screws	#8 - 32 Steel - Zinc plated (Philips / Slotted / Robertson)

Performance

Electrical


Current Interrupting Certified for full rated current
 Dielectric Voltage Withstands 2,000V minimum

Mechanical

Terminal Accommodation #18 AWG - #10 AWG stranded copper wire only.

Environmental

Flammability HB or better per UL 94 or CSA 22.2 No. 0.6
 Moisture Resistance IP20 Suitability
 Operating Temperatures Maximum Continuous 75°C Minimum -40°C (w/o impact)
 Terminal Identification Terminals identified in accordance with UL 498

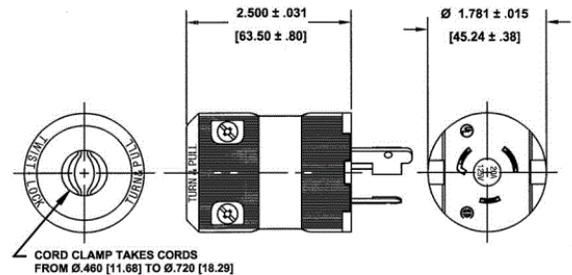

Accessories

Connector	HBL2333VY
Single Receptacle	HBL2330
Flanged Receptacle	HBL2336
Weatherproof Boot	HBL60CM31V

Resources

Customer Use Drawing
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

