

HyFlex®

ADVANCED MECHANICAL PROTECTION

11-920

Light duty oil repellent, oil grip multi-purpose glove



Oil

LD

Light Duty

High performance grip and oil repellence

- Multi-layer coating provides high abrasion resistance and increases wear life
- Ergonomic, natural fit along with superior dry and oil grip for high productivity
- Durable material is machine launderable for extended life and reduced replacement costs



Industries

- Automotive
- Machinery and Equipment
- Metal fabrication
- Oil and gas

Applications

- Assembly & inspection of components
- Production line support & maintenance
- Seizing structural parts
- Fabricating metal parts, glass sheets
- Applying finish to materials, products

HyFlex®

ADVANCED MECHANICAL PROTECTION

11-920


Light duty oil repellent, oil grip multi-purpose glove

Key Features

- HyFlex® 11-920 glove provide high performance grip and oil repellence when working in oily environments
- ANSELL GRIP™ Technology contains microscopic channels in the glove coating to displace oil, resulting for a more secure grip when handling oily parts
- RIPEL™ Liquid Repellence Technology creates a liquid impermeable layer to prevents oil or lubricant from making contact with the wearer's skin, enhancing hand health
- Seamless knit design provide an outstanding fit, comfort and dexterity to maximize all-day productivity
- Also available in vend pack

Performance Standards & Regulatory Compliance

REACH Compliant

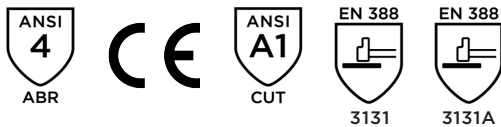

Technologies

 **ANSELL GRIP™**
Ansell Grip Technology

 **RIPEL™**
Liquid Repellence Technology

Specifications

BRAND STYLE	DESCRIPTION	Gauge	SIZE	LENGTH	COLOR	PACKAGE
HyFlex® 11-920	Finishing: Palm Coated Coating Material: Nitrile Liner Material: Nylon Cuff Style: Knitwrist	15	6, 7, 8, 9, 10	208-270 mm/ 8.18-10.62 inches	Blue	• 12 pairs in a bag; 12 bags in a carton

For additional information visit us at www.ansell.com, or call us at

Europe, Middle East & Africa Region

Ansell Healthcare Europe NV
Riverside Business Park
Blvd International, 55
1070 Brussels, Belgium
T: +32 (0) 2 528 74 00
F: +32 (0) 2 528 74 01

North America Region

Ansell Healthcare Products LLC
111 Wood Avenue South,
Suite 210
Iselin, NJ 08830, USA
T: +1 800 800 0444
F: +1 800 800 0445

Australia

Ansell Limited
Level 3,678 Victoria Street,
Richmond, Vic, 3121
Australia
T: +61 1800 337 041
F: +61 1800 803 578

Asia Pacific Region

Ansell Global Trading Center
(Malaysia) Sdn Bhd
Prima 6, Prima Avenue
Block 3512, Jaijan Teknokrat 6
T: +603 8310 6688
F: +603 8310 6699

Latin America & Caribbean Region

Ansell Commercial Mexico S.A. de C.V.
Blvd. Bernardo Quintana No. 7001-C,
Q7001 Torre II,
Suites 1304, 1305 y 1306,
Col. Centro Sur, c.p. 76079
Queretaro, Qro. Mexico
T: +52 442 248 1544 / 248 3133

Canada

Ansell Canada
105 Lauder
Cowansville, QC J2K 2K8
Canada
T: +1 800 363 8340
F: +1 800 267 3551

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending:
www.ansell.com/patentmarking © 2021 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.

