


At 18" in depth, the K1800 allows for storage in tight spaces.



Double wall construction

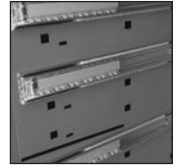

Smooth operating ball-bearing drawer slides range from 120-240 lbs.



High security tubular locking system




Heavy-duty 5" x 2" roller bearing casters with 350 lb. capacity per caster



Tubular steel end handle



AVAILABLE COLORS

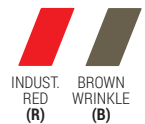

INDUSTRY SOLUTIONS

The K1800 Series is best used in the following:





315X
15-DRAWER CABINET

- 5" x 2" roller bearing casters hold up to 350 lbs. each
- Dual locks



310X
10-DRAWER CABINET

- 5" x 2" Roller bearing casters hold up to 350 lbs. each
- Dual locks

PART #		SPECIFICATIONS								STEEL GAUGE	
		DRS.	WIDTH	DEPTH	HEIGHT	LINER *	NET / SHIP WT.	STORAGE	CAPACITY	BODY	DRAWERS
310X	10-Drawer Cabinet	10	39 3/8"	18"	35"	-	180 / 210 lbs.	11,865 cu. in.	-	18 ga	20 ga
	Left Bank	3	23"	16 1/2"	3 5/8"	84037	-	-	120 lbs.	-	20 ga
		2	23"	16 1/2"	5 5/8"	84037	-	-	120 lbs.	-	20 ga
	Right Bank	3	9 1/2"	16 1/2"	3 5/8"	84039	-	-	120 lbs.	-	20 ga
		2	9 1/2"	16 1/2"	5 5/8"	84039	-	-	120 lbs.	-	20 ga
315X	15-Drawer Cabinet	15	39 3/8"	18"	39"	-	230 / 260 lbs.	13,382 cu. in.	-	18 ga	20 ga
	Left Bank	5	23"	16 1/2"	1 5/8"	84037	-	-	120 lbs.	-	20 ga
		3	23"	16 1/2"	3 5/8"	84037	-	-	120 lbs.	-	20 ga
		1	23"	16 1/2"	5 5/8"	84037	-	-	120 lbs.	-	20 ga
	Right Bank	2	9 1/2"	16 1/2"	1 5/8"	84039	-	-	120 lbs.	-	20 ga
		3	9 1/2"	16 1/2"	3 5/8"	84039	-	-	120 lbs.	-	20 ga
		1	9 1/2"	16 1/2"	11 5/8"	84039	-	-	240 lbs.	-	20 ga

* Liners sold separately



AVAILABLE COLORS

Customize the color of your products. Simply place one of the abbreviations at the end of the model number.



MADE IN THE USA



378X
8-DRAWER CABINET

- 5" x 2" roller bearing casters hold up to 350 lbs. each




285X
5-DRAWER TOP CHEST

- Fits 27" wide roller cabinets
- Ball bearing drawer slides

PART #	SPECIFICATIONS	STEEL GAUGE								
		DRS.	WIDTH	DEPTH	HEIGHT	LINER *	NET / SHIP WT.	STORAGE	CAPACITY	BODY
285X 5-Drawer Top Chest	5	27"	18"	16 1/2"	-	75 / 105 lbs.	3,842 cu. in.	-	18 ga	20 ga
	Drawers	4	23"	16 1/2"	1 5/8"	84037	-	120 lbs.	-	20 ga
	1	23"	16 1/2"	3 5/8"	84037	-	-	120 lbs.	-	20 ga
378X 8-Drawer Cabinet	8	27"	18"	39"	-	154 / 184 lbs.	9,488 cu. in.	-	18 ga	20 ga
	Drawers	3	23"	16 1/2"	1 5/8"	84037	-	120 lbs.	-	20 ga
	4	23"	16 1/2"	3 5/8"	84037	-	-	120 lbs.	-	20 ga
	1	23"	16 1/2"	5 5/8"	84037	-	-	120 lbs.	-	20 ga

* Liners sold separately

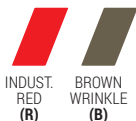

AVAILABLE COLORS

Customize the color of your products. Simply place one of the abbreviations at the end of the model number.



MADE IN THE USA



277X
7-DRAWER CABINET

- 5" x 2" roller bearing casters hold up to 350 lbs. each



275X
5-DRAWER CABINET

- 5" x 2" roller bearing casters hold up to 350 lbs. each
- Swing down panel conceals & secures spacious storage compartment



273X
3-DRAWER CABINET

- 5" x 2" roller bearing casters hold up to 350 lbs. each
- Swing down panel conceals & secures spacious storage compartment




185X
5-DRAWER SIDE CABINET

- Fits Models 273X, 275X, 277X, 310X
- Hangs on either side of rolling cabinet
- Ball bearing drawer slides

* Liners sold separately

PART #	SPECIFICATIONS	STEEL GAUGE									
		DRS.	WIDTH	DEPTH	HEIGHT	LINER *	NET / SHIP WT.	STORAGE	CAPACITY	BODY	DRAWERS
273X 3-Drawer Cabinet		3	27"	18"	35"	-	102 / 132 lbs.	9,330 cu. in.	-	18 ga	20 ga
	Drawers	2	23"	16 1/2"	3 3/8"	84037	-	-	120 lbs.	-	20 ga
		1	23"	16 1/2"	5 5/8"	84037	-	-	120 lbs.	-	20 ga
	Compartment	-	24 1/8"	16 3/8"	11 1/4"	-	-	-	120 lbs.	-	20 ga
275X 5-Drawer Cabinet		3	27"	18"	35"	-	115 / 135 lbs.	9,046 cu. in.	-	18 ga	20 ga
	Drawers	3	23"	16 1/2"	1 5/8"	84037	-	-	120 lbs.	-	20 ga
		2	23"	16 1/2"	3 3/8"	84037	-	-	120 lbs.	-	20 ga
	Compartment	-	24 1/8"	16 3/8"	11 1/4"	-	-	-	-	-	20 ga
277X 7-Drawer Cabinet		7	27"	18"	35"	-	134 / 164 lbs.	8,404 cu. in.	-	18 ga	20 ga
	Drawers	3	23"	16 1/2"	1 5/8"	84037	-	-	120 lbs.	-	20 ga
		3	23"	16 1/2"	3 3/8"	84037	-	-	120 lbs.	-	20 ga
		1	23"	16 1/2"	5 5/8"	84037	-	-	120 lbs.	-	20 ga
185X 5-Drawer Side Cabinet		5	13 3/8"	18"	29 1/8"	-	72 / 97 lbs.	3,468 cu. in.	-	18 ga	20 ga
	Drawers	1	9 1/2"	16 1/2"	1 5/8"	84039	-	-	120 lbs.	-	20 ga
		3	9 1/2"	16 1/2"	3 3/8"	84039	-	-	120 lbs.	-	20 ga
		1	9 1/2"	16 1/2"	9 5/8"	84039	-	-	240 lbs.	-	20 ga

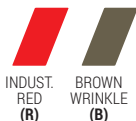

AVAILABLE COLORS

Customize the color of your products. Simply place one of the abbreviations at the end of the model number.



MADE IN THE USA



21040B shown with 520B



21040B shown with 620B

21040 4-DRAWER CABINET

- 5" x 1-1/4" roller bearing casters hold up to 200 lbs. each
- Ball bearing drawer slides & tubular push handle
- Small in size, but big on security!
- Tubular locking system
- Compatible chests & bases: 520, 620, 220, K20

PART #	SPECIFICATIONS	STEEL GAUGE									
		DRS.	WIDTH	DEPTH	HEIGHT	LINER *	NET / SHIP WT.	STORAGE	CAPACITY	BODY	DRAWERS
21040	4-Drawer Cabinet	4	20 1/2"	18"	33 3/4"	-	103 / 133 lbs.	5,717 cu. in.	-	18 ga	20 ga
	Drawers	2	16 1/2"	16 1/2"	2 3/4"	84038	-	-	120 lbs.	-	20 ga
		1	16 1/2"	16 1/2"	6 1/8"	84038	-	-	120 lbs.	-	20 ga
		1	16 1/2"	16 1/2"	9 3/8"	84038	-	-	120 lbs.	-	20 ga

* Liners sold separately



AVAILABLE COLORS

Customize the color of your products. Simply place one of the abbreviations at the end of the model number.



MADE IN THE USA