



**MCR  
SAFETY**

**6914**

**Memphis NeoMax  
Supported / Dipped gloves  
Specification Sheet**

**PRODUCT DESCRIPTION:**

Not only does the NeoMax have a great name, but it offer outstanding protection. The 6912 features a 14 inch green double dipped glove with a brushed interlock liner. The sandy finish helps you get a grip and the lining is treated with ActiFresh® that will prevent bacterial build up and resist molds and mildew. Go to the Max with NeoMax™.

**FEATURES:**

- Green Double Dipped Neoprene
- 100% Cotton Brushed Interlock Liner
- Treated with Actifresh®
- 14 Inch Length
- Sandy Finish
- Component materials comply with all federal regulations for food contact

**APPLICATIONS:**

Agriculture, Carpentry, Construction, Farming, Janitorial , Oil and Gas Industry, Plumbing, Sanitation, Food



**TECHNICAL DATA FOR: 6914**

<b>Series</b>	Memphis NeoMax	<b>Overall Length</b>	14 in.
<b>Material Group</b>	Supported	<b>EN 388 : CE Score - Abrasion</b>	2
<b>Product Type</b>	Supported / Dipped gloves	<b>EN 388 : CE Score - Cut</b>	1
<b>Glove Size</b>	Large	<b>EN 388 : CE Score - Tear</b>	2
<b>Material</b>	Neoprene	<b>EN 388 : CE Score - Puncture</b>	1
<b>Grade</b>	Industrial Grade	<b>FDA Accepted Materials</b>	FDA Compliant
<b>Lining</b>	Brushed Interlock		
<b>Thumb Style</b>	Wing		

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: [www.mcrcsafety.com](http://www.mcrcsafety.com)


©2018 MCR Safety - All Rights Reserved



**MCR**  
SAFETY

# 6914

## Memphis NeoMax Supported / Dipped gloves Specification Sheet

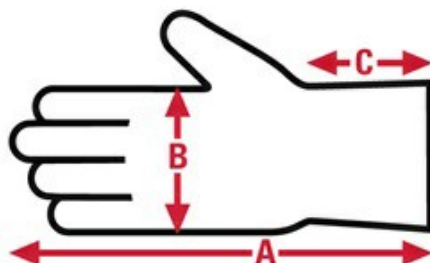

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
6914L	Large	14.160	6.200	N/A	33.306 lb.	5.551
6914M	Medium	13.840	6.200	N/A	30.780 lb.	5.130
6914S	Small	13.680	5.680	N/A	30.198 lb.	5.033
6914XL	X - Large	14.320	6.200	N/A	35.610 lb.	5.935

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: [www.mcrcsafety.com](http://www.mcrcsafety.com)

©2018 MCR Safety - All Rights Reserved