



**MCR
SAFETY**

9782

Predaknit

**Supported / Dipped gloves
Specification Sheet**

PRODUCT DESCRIPTION:

The Predaknit® offers you outstanding protection and comfort you will appreciate through the day. The 9782 features a full premium nitrile coating on a soft interlock liner for comfort. The 12 inch cuff ensures additional protection and the rough texture offers extra grip. Actifresh is added to help reduce odor and bacteria.

FEATURES:

- Premium Nitrile Coating
- Interlock lining
- 12 inch gauntlet cuff
- Rough finish
- CE score 3121

APPLICATIONS:

Agriculture, Carpentry, Construction, Farming, Landscaping, Material Handling, Food, Oil and Gas Industry, Dairy



TECHNICAL DATA FOR: 9782

Series	Predaknit
Material Group	Supported
Product Type	Supported / Dipped gloves
Glove Size	Large
Material	Nitrile
Grade	Industrial Grade
Lining	Interlock
Thumb Style	Straight

Overall Length	12 in.
EN 388 : CE Score - Abrasion	4
EN 388 : CE Score - Cut	1
EN 388 : CE Score - Tear	2
EN 388 : CE Score - Puncture	2
FDA Accepted Materials	FDA Compliant

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved




MCR
SAFETY

9782

Predaknit

Supported / Dipped gloves

Specification Sheet

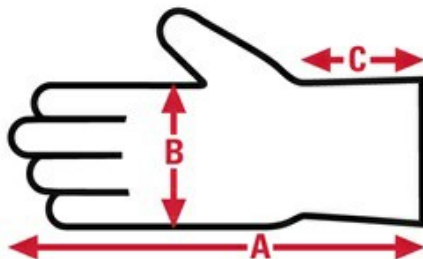

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
9782L	Large	11.890	6.339	N/A	43.152 lb.	3.596
9782M	Medium	11.732	6.024	N/A	39.192 lb.	3.266
9782S	Small	11.456	5.197	N/A	35.916 lb.	2.993
9782XL	X - Large	12.166	6.654	N/A	44.916 lb.	3.743
9782XXL	XX - Large	0	0	N/A	45.996 lb.	3.833

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved