



**MCR
SAFETY**

6524S

Supported / Dipped gloves Specification Sheet

PRODUCT DESCRIPTION:

Best bang for your buck. PVC offers unmatched performance at an affordable cost. Double dipped PVC coated gloves provide excellent protection. Glove lengths from knit wrist to 18" provide different levels of protection. The 6524S is an industry standard black double dipped, sandy finish, interlock lined glove with a gauntlet cuff. Glove is 14" in length.

FEATURES:

- PVC
- Black Double Dipped
- Interlock
- Sandy Finish
- 14 inch


APPLICATIONS:

Agriculture, Dairy, Farming, Janitorial, Material Handling, Sanitation, Petrochemical industries



TECHNICAL DATA FOR: 6524S

Material Group	Supported	Overall Length	14 in.
Product Type	Supported / Dipped gloves		
Glove Size	Large		
Material	PVC		
Grade	Industrial Grade		
Lining	Interlock		
Thumb Style	Wing		

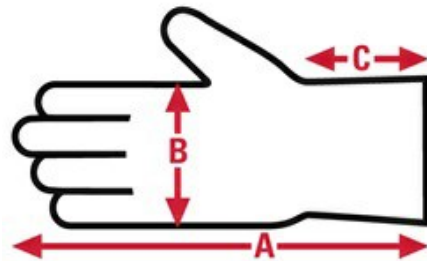



MCR
SAFETY

6524S

Supported / Dipped gloves
Specification Sheet

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
6524S	Large	11.000	6.09	N/A	35.694 lb.	5.949

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved