

CHROME SLT®



Elastic cuff with Velcro® closure for a secure fit

Pull tab

Grip in dry or light oil situations

Synthetic leather palm with abrasion-resistant PVC dots

Hi-vis color on back-of-hand

HPPE blend liner provides 360° industry-leading cut resistance (interior layer)

Back-of-hand impact guards provide ANSI/ISEA 138 Level 1 protection on knuckles and fingers

High dexterity

Reinforced Seams

Form-fitting, quality materials


Launderable



4070

Chrome SLT® 360°

PROTECTION ZONES:

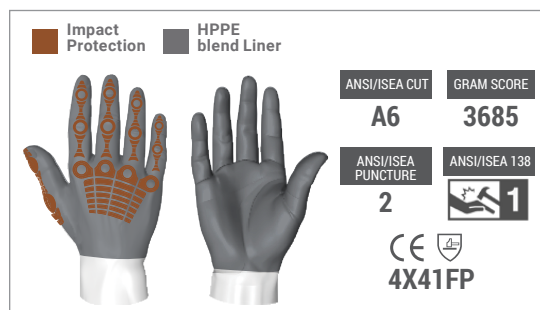

FEATURES:

HexArmor® Chrome SLT® gloves are built for a wide array of applications. Each product in the series was crafted to fit the hand with a specific purpose. With multiple styles and various safety features, you can be confident that the Chrome SLT® will keep your hands protected against almost any hazard. Our Chrome SLT® gloves were designed with ultimate comfort in mind, providing unsurpassed dexterity while maintaining cut and puncture resistance. With options for cold weather protection, your hands can stay safe and comfortable in any environment.

ATTRIBUTES:

Style:	Mechanics
Grip:	Dry or light oil
Cuff Style:	Elastic with Velcro® closure
Sizes:	6/XS through 12/3XL

HexArmor®

Call **1-877-MY ARMOR** or visit **hexarmor.com**

HexArmor® products are cut and puncture resistant, NOT CUT AND PUNCTURE PROOF. Do not use with moving or serrated blades or tools. User shall be exclusively responsible to assess the suitability of the product as specified for any individual application or use. Protection zones are to be used as a general guide. Actual product protection zones may differ. Product features, design, protection zones subject to change.

Protected by patents and patents pending