



MCR
SAFETY

9751 Predator

Supported / Dipped gloves Specification Sheet

PRODUCT DESCRIPTION:

The protection the Predator® gloves offer is unmatched in the market giving you the advantage over what you will face at work today. The 9751 Predator® features premium fully coated nitrile on a soft jersey liner treated with Actifresh. Comfortable knit wrist.

FEATURES:

- Premium Nitrile, Fully Coated
- Soft Jersey Lining
- Treated with Actifresh
- Knit Wrist
- CE Score 4212

APPLICATIONS:

Agriculture, Carpentry, Construction, Demolition, Farming, Forestry, Landscaping, Lumber industry, Material Handling



TECHNICAL DATA FOR: 9751

Series	Predator
Material Group	Supported
Product Type	Supported / Dipped gloves
Glove Size	Large
Material	Nitrile
Grade	Premium
Lining	Jersey
Thumb Style	Straight

Overall Length	11 in.
EN 388 : CE Score - Abrasion	4
EN 388 : CE Score - Cut	2
EN 388 : CE Score - Tear	2
EN 388 : CE Score - Puncture	1

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com


©2018 MCR Safety - All Rights Reserved



MCR
SAFETY

9751 Predator

Supported / Dipped gloves
Specification Sheet

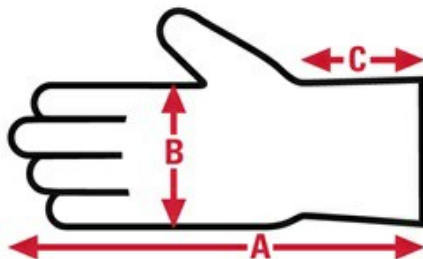

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
9751	Large	10.827	6.360	3.000	43.116 lb.	3.593

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved