



**MCR
SAFETY**

N9676GKD

Ninja

Cut Protection Specification Sheet

PRODUCT DESCRIPTION:

Each of the offerings in the Ninja® series include a unique shell and polymer combination incorporating the latest in hand protection technology. Our Ninja® Glove Line offers the greatest assortment of dexterity, sense of touch, and protection. Common features to all styles include individual packaging for point of sale presentation, treated with Actifresh® to kill bacteria and promote freshness, and available in sizes small through extra large. MCR Safety is a licensed supplier of gloves made with Dyneema®. The N9676GKD is a 10 gauge blended Dyneema® and synthetic yarn with a bi-polymer coating that extends over the knuckle area.



FEATURES:

- 10 gauge gray Dyneema® blended shell
- Black foam bi-polymer coated - over the knuckle
- Cut Resistant
- ANSI Level 3
- CE 4542

APPLICATIONS:

Automotive Assembly, Bottling, Canning, Glass handling, HVAC, Sheet metal industry, Construction, Farming, Janitorial, Roofing

TECHNICAL DATA FOR: N9676GKD

Series	Ninja	EN 388 : CE Score - Cut	5
Material Group	Synthetic	ANSI Cut	ANSI Cut A3
Product Type	Cut Protection	ANSI Puncture	ANSI Puncture 3
Glove Size	Large	ANSI Abrasion	ANSI Abrasion 5
Gauge	10 Gauge		
Material	Dyneema		

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved




MCR
SAFETY

N9676GKD

Ninja

Cut Protection Specification Sheet

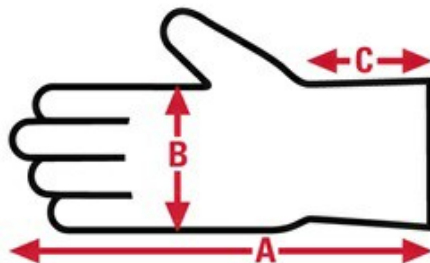

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
N9676GKDL	Large	0	0	N/A	37.152 lb.	0.258
N9676GKDM	Medium	0	0	N/A	35.856 lb.	0.249
N9676GKDS	Small	0	0	N/A	30.528 lb.	0.212
N9676GKDXL	X - Large	0	0	N/A	42.768 lb.	0.297

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved