



**MCR
SAFETY**

N9690FCO

Ninja

Dipped

Specification Sheet

PRODUCT DESCRIPTION:

Memphis Ninja® gloves are engineered to provide the highest level of innovation. Each of the offerings in the Ninja® series include a unique shell and polymer combination incorporating the latest in hand protection technology. The Memphis Ninja® Glove Line offers the greatest assortment of dexterity, sense of touch, and protection. The Ninja® Ice Fully Coated Orange gloves features a 15 gauge orange nylon shell with a 7 gauge acrylic terry interior liner. Orange HPT fully coated glove.

FEATURES:

- Acrylic Terry liner for insulation / warmth.
- Orange HPT repels liquids while providing strong wet or dry grip
- Fully coated for maximum protection Coating remains soft in temperatures as low as -58 F
- CE score 3232; CE/EN 511 cold hazard 02X
- Medium through Extra large



APPLICATIONS:

Agriculture, Airport , Cold storage applications, Farming, Flagman

TECHNICAL DATA FOR: N9690FCO

Series	Ninja	EN 388 : CE Score - Abrasion	3
Material Group	Strings	EN 388 : CE Score - Cut	2
Product Type	Dipped	EN 388 : CE Score - Tear	3
Glove Size	Large	EN 388 : CE Score - Puncture	2
Gauge	15 / 7 Gauge	ANSI Cut	ANSI Cut A3
Material	Nylon / Acrylic	ANSI Puncture	ANSI Puncture 2
Insulated	Insulated	ANSI Abrasion	ANSI Abrasion 3
Lining	Acrylic	ANSI Contact Heat	Level 2 (Applications less than 284 degrees F)
HI VIS	High Visibility		

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved




MCR
SAFETY

N9690FC0

Ninja

Dipped

Specification Sheet

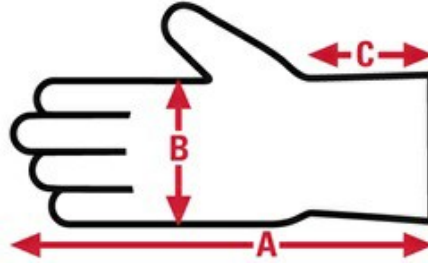

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
N9690FCOL	Large	11.02	5.60	N/A	26.838 lb.	4.473
N9690FCOM	Medium	9.84	5.35	N/A	26.100 lb.	4.350
N9690FCOXL	X - Large	11.02	5.80	N/A	26.460 lb.	4.410
N9690FCOXXL	XX - Large	11.412	6.13	N/A	30.660 lb.	5.110

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved