



**MCR
SAFETY**

9781 Predalite

Supported / Dipped gloves Specification Sheet

PRODUCT DESCRIPTION:

Although this glove is light in weight, it is a heavy weight at heart. The Predalite® can stand up to the toughest environments. The Predalite® 9781 features an interlock liner treated with Actifresh, fully coated light nitrile, and a comfortable knit wrist.

FEATURES:

- Fully coated with nitrile
- Interlock lining
- Knit wrist
- CE Score 4121
- Treated with Actifresh to reduce odors

APPLICATIONS:

Food, Oil and Gas Industry



TECHNICAL DATA FOR: 9781

Series	Predalite	Overall Length	10.5 in.
Material Group	Supported	EN 388 : CE Score - Abrasion	4
Product Type	Supported / Dipped gloves	EN 388 : CE Score - Cut	1
Glove Size	Large	EN 388 : CE Score - Tear	2
Material	Nitrile	EN 388 : CE Score - Puncture	1
Grade	Premium	FDA Accepted Materials	FDA Compliant
Lining	Interlock		
Thumb Style	Straight		

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com


©2018 MCR Safety - All Rights Reserved



MCR
SAFETY

9781 Predalite

Supported / Dipped gloves
Specification Sheet

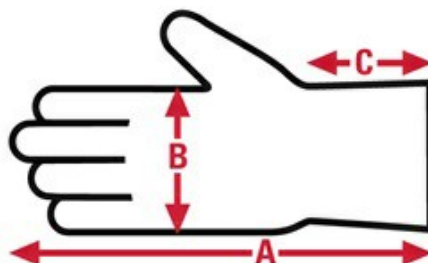

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
9781L	Large	10.629	5.827	N/A	32.004 lb.	2.667
9781M	Medium	10.433	5.433	N/A	27.924 lb.	2.327
9781S	Small	10.237	5.118	N/A	27.396 lb.	2.283
9781XL	X - Large	10.827	6.181	N/A	32.424 lb.	2.702

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved