

Straight Blade Devices

15 Amp, 125 Volt, 2-Pole, 3-Wire

SNAPConnect<sup>®</sup> Extra Heavy Duty Receptacle



- Features
- Audible SNAP, indicates solid connection
  - Reduces installation time
  - Tamper-Resistant
  - Assembled in USA

Ordering Information

Description	Device Color	UPC Number	Catalog Number
Standard Duplex	White	783585552828	SNAP5262WTRA

Listings


UL Listed to UL498 File No. E2412  
Certified to CSA, C22.2, No. 42 File 511  
Fed. Spec. W-C-822  
NEMA® WD-6 Compliant

Specifications

Face	Nylon
Base	Nylon
Line Contact	Brass
Ground Contact	Brass

Performance

<b>Electrical</b>	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum
<b>Mechanical</b>	
Product Identification	Ratings are a permanent part of the device
<b>Environmental</b>	
Flammability	UL 94V-2
Operating Temperature	Maximum continuous 75°C; minimum -40°C (without impact)

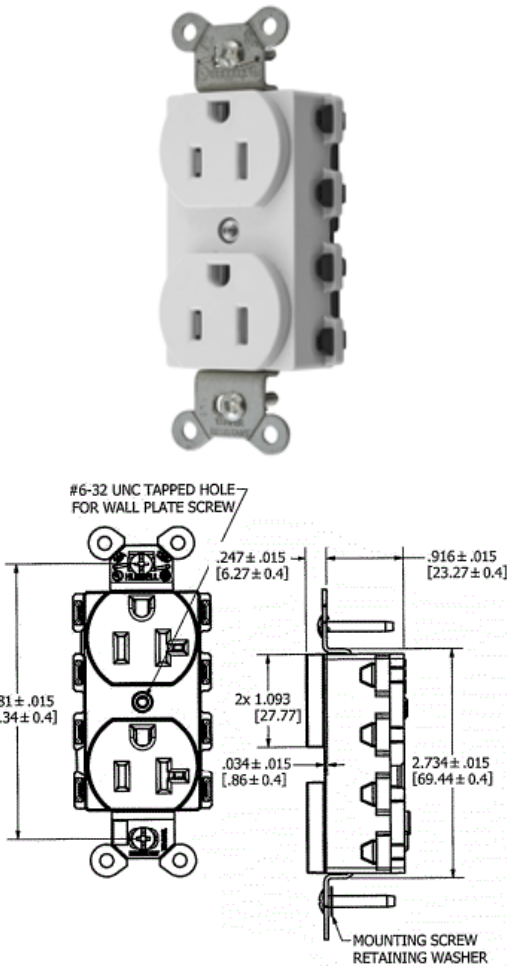

Complementary Products

Wallplate or Weatherproof Cover  
Opening

Online Resources

Customer Sales Drawing  
eCatalog  
Installation Instructions

