

Straight Blade Devices

 
 

 


Heavy Duty, Specification Grade Receptacles

15A and 20A 125V and 250V Receptacles and Equipment Base Devices


TECH-SPEC®




		Receptacles				Equipment Base Devices - Clamp-Type, Back Wiring			
Style		Duplex		Decotator	Single	Male		Female	
Rating	Color	Back and Side Wired	Side Wired	Back and Side Wired	Side Wired	Color	Nylon Cup	Self-Grounding Strap	Nylon Cup
NEMA 5-15, 15A 125V 	Black	5262BBLK	5242BLK	9252BLK	—	Black	—	5278G	—
	Brown	5262BN	5242	9252	5251	White	5278	—	5279
	Gray	5262BGRY	5242GRY	9252GRY	—				
	Ivory	5262BI	5242I	9252I	5251I				
	Red	5262BRED	5242RED	—	—				
White	5262BW	5242W	9252W	—					
NEMA 5-20, 20A 125V 	Black	5362BBLK	5342BLK	9352BLK	5351BLK	Black	—	5378G	—
	Brown	5362BN	5342	9352BRN	5351	White	5378	—	5379
	Gray	5362BGRY	5342GRY	9352GRY	—				
	Ivory	5362BI	5342I	9352I	5351I				
	Red	5362BRED	5342RED	—	—				
White	5362BW	5342W	9352W	—					
NEMA 6-15, 15A 250V 						White	5678	5678G	5679
NEMA 6-20, 20A 250V 						White	5478	—	5479

Product Dimensions Inches (mm)


	Receptacle			Equipment Devices	
	Duplex	Decorator	Single	Male	Female
A	4.06" (103.1)	4.06" (103.1)	4.06" (103.1)	1.84" (46.7)	1.84" (46.7)
B	3.28" (83.3)	3.28" (83.3)	3.28" (83.3)	2.00" (50.8)	2.00" (50.8)
C	1.38" (35.1)	1.36" (34.5)	1.38" (35.1)	2.50" (63.5)	2.50" (63.5)
D	0.92" (23.4)	1.03" (26.2)	0.92" (23.4)	1.61" (40.9)	1.47" (37.3)
E	2.68" (68.1)	2.75" (69.9)	1.78" (45.2)	1.55" (39.4)	1.31" (33.3)

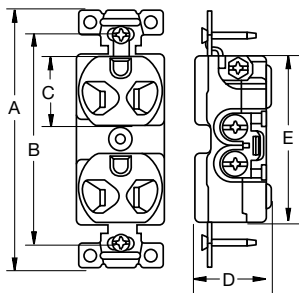


Duplex Receptacle

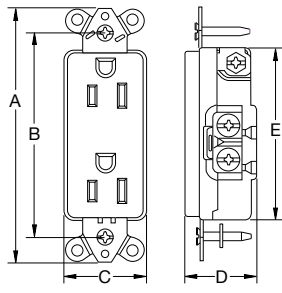


Duplex Receptacle

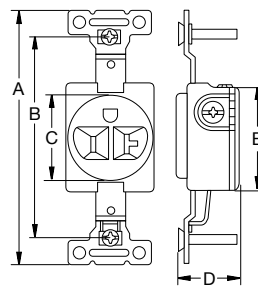

Single Receptacle

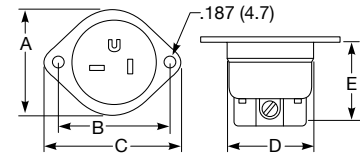

Male Equipment Device

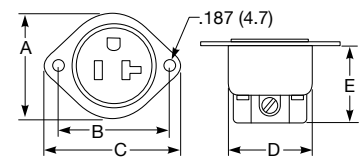

Female Equipment Device