

Corrosion-Resistant Devices

15 and 20 Amp Straight Blade Devices



- Nickel-plated copper-alloy metallic components
- Molded of impact/chemical resistant high-visibility yellow nylon
- Stainless steel screws
- Receptacles have a one-piece grounding system with built-in self-grounding strap
- Triple Gripper® cord grip on plugs and connectors which feature three captive assembly screws to automatically tighten cord grip
- Pre-attached thermoplastic elastomer dust seal

15A and 20A Straight Blade Plugs, Connectors and Receptacles Inches (mm)

TECH·SPEC®




Rating Plug Connector	Cord Diameter	Poles/Wires	Color	Nylon Polymer Plug	Nylon Polymer Connector	Nylon Receptacle, Back and Side Wired	
						Single	Duplex
NEMA 5-15 15A 125V  	.300"-.625" (7.6-15.9)	2-Pole 3-Wire	Yellow Brown	BRY5266NPCR —	BRY5269NCCR —	5261CR* —	BRY5262CR BRY5262BCR
NEMA 5-20 20A 125V  	.300"-.625" (7.6-15.9)	2-Pole 3-Wire	Yellow	BRY5366NPCR	BRY5369NCCR	5361CR*	BRY5362CR
NEMA 6-15 15A 250V  	.300"-.625" (7.6-15.9)	2-Pole 3-Wire	Yellow	—	—	—	BRY5662CR
NEMA 6-20 20A 250V  	.300"-.625" (7.6-15.9)	2-Pole 3-Wire	Yellow	—	—	5461CR*	BRY5462CR


Note: *Not Fed. Spec.
See page A-27 for information on weather protective boots.
See page R-8 for horsepower ratings.

Product Dimensions Inches (mm)

Plug	
A	2.18" (55.4)
B	1.38" (35.1)
C	1.52" (38.5)

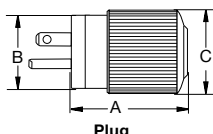

Connector	
A	2.95" (74.9)
B	1.38" (35.1)
C	1.52" (38.5)

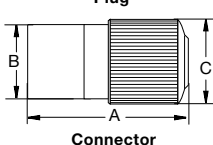

	Receptacle	
	Single	Duplex
A	4.06" (103.1)	4.06" (103.1)
B	3.28" (83.3)	3.28" (83.3)
C	1.38" (35.1)	1.54" (39.1)
D	.91" (23.1)	.92" (23.4)
E	1.78" (45.2)	2.69" (68.3)

