


STAINLESS STEEL

HEX - SOCKET PLUG

Features:

- Pipe size from 1/16" to 2" in diameter
- NPT threads
- Max. pressure: 150PSI
- Temperature -60°F to 450°F

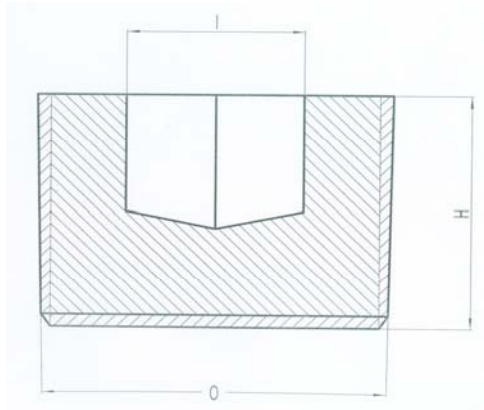

Unit: Inch

Grainger #	Material	Pipe Size	Thread Size	Hex Size	Length (H)
4WPK1	SS 304#	1/16	1/16	5/32	5/16
4WPK2	SS 304#	1/8	1/8	3/16	5/16
4WPK3	SS 304#	1/4	1/4	1/4	7/16
4WPK4	SS 304#	3/8	3/8	5/16	1/2
4WPK5	SS 304#	1/2	1/2	3/8	9/16
4WPK6	SS 304#	3/4	3/4	9/16	5/8
4WPK7	SS 304#	1	1	5/8	3/4
4WPK8	SS 304#	1 1/4	1 1/4	3/4	13/16
4WPK9	SS 304#	1 1/2	1 1/2	1	55/64
4WPL1	SS 304#	2	2	1	15/16
4WPL2	SS 316#	1/8	1/8	3/16	5/16
4WPL3	SS 316#	1/4	1/4	1/4	7/16
4WPL4	SS 316#	3/8	3/8	5/16	1/2
4WPL5	SS 316#	1/2	1/2	3/8	9/16
4WPL6	SS 316#	3/4	3/4	9/16	5/8
4WPL7	SS 316#	1	1	5/8	3/4
4WPL8	SS 316#	1 1/4	1 1/4	3/4	13/16
4WPL9	SS 316#	1 1/2	1 1/2	1	55/64
4WPN1	SS 316#	2	2	1	15/16