

ProTac® 2L-X USB / ProTac® 2L-X

MULTI FUEL - 18650 USB LI-ION RECHARGEABLE or 2X CR123 FLASHLIGHT

MARKET

APPLICATIONS: Professional Light - Hardware/Tool, Industrial, Law Enforcement, Security, Automotive, Sporting Goods, Consumer.

DESCRIPTION:

The ProTac® 2L-X USB or ProTac® 2L-X are 500 lumen EDC tactical lights that can use either a proprietary Streamlight 18650 USB rechargeable Li-Ion battery or Two CR123A disposable batteries. The ProTac® 2L-X USB is a complete rechargeable system that comes with a charge cord and an 18650 button top battery that features an integrated micro-USB charge port. The ProTac® 2L-X comes packaged with two CR123A batteries. Both lights feature a tactical tail cap switch for momentary or constant on operation, three different user selectable programs and a pocket clip for convenience. The aluminum housing with Type II Military Spec anodizing helps make the lights extremely durable and abrasion resistant. Packaged with a removable pocket clip and holster. Available in Black.

CASE MATERIAL:

6000 series machined aircraft aluminum with Type II MIL-Spec anodized finish. Available in Black.

DIMENSIONS:

Length: 5.14 in. (13.0 cm) Head Diameter: 1.06 in. (2.7 cm) Body Diameter: .940 in. (2.4 cm)

WEIGHT:

ProTac® 2L-X USB: 4.4 oz (125 grams) with one Streamlight 18650 USB Li-Ion battery (included in purchase).

ProTac® 2L-X: 3.9 oz (111 grams) with two CR123A batteries (included in purchase).

LENS:

Glass lens; gasket sealed.

LIGHT SOURCE:

C4® LED technology, impervious to shock with a 50,000 hour lifetime.

LIGHT OUTPUT:

See chart. Fully regulated output for consistent lumen performance over the battery life.

ON/OFF:

Multi-function, push-button tactical tail switch. One handed operation of momentary, variable intensity or strobe mode. TEN-TAP® programmable switch allows user selection of one of three different programs: high/strobe/low (factory default), high only, or low/high.

RUN TIME:

See charts for specific battery type. All runtime claims are to 10% of initial lumen output.

BATTERY:

One (1) Streamlight 18650 USB Li-Ion protected 3.7V, 2600 mAh rechargeable battery, recharges in 5 hours.

Two (2) 3 Volt CR123A Lithium batteries with a storage life of 10 years.

FEATURES:


C4® LED technology for extreme brightness.

IPX7 rated design; waterproof to 1 meter for 30 minutes. All openings o-ring sealed.

2 meter impact resistance tested.

Multi fuel; accepts 18650 Li-Ion or CR123A batteries.

TEN-TAP® programmable switch allows user to select one of three different programs.

Anti-roll face cap.

Serialized for positive identification.

Removable pocket clip and Holster

APPROVALS:

 Meets applicable European Community Directives.

 CEC compliant (ProTac® 2L-X USB only)

WARRANTY:

Streamlight's Limited Lifetime Warranty

OPTIONAL
ACCESSORIES:

Holster, Charge cords.

WITH CR123A BATTERIES


	FL1 STANDARD	HIGH	LOW
OUTPUT		500 LUMENS	40 LUMENS
RUNTIME		2h45m	30h
DISTANCE		165m	49m
INTENSITY		6,800cd	600cd

Strobe Run Time: 3 Hr 15 Min

WITH 18650 RECHARGEABLE BATTERY

	FL1 STANDARD	HIGH	LOW
OUTPUT		500 LUMENS	40 LUMENS
RUNTIME		3h15m	30h
DISTANCE		165m	49m
INTENSITY		6,800cd	600cd

Strobe Run Time: 4.5 Hours

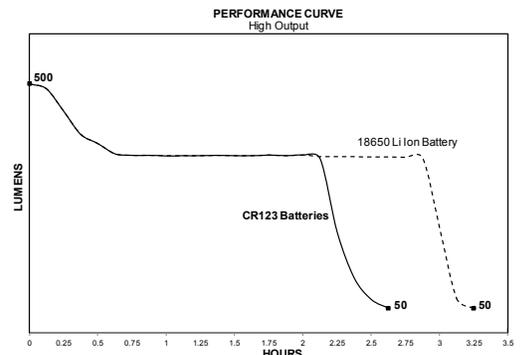

All performance claims to ANSI/PLATO FL1-2016 Standard

Issued: 7/19/2016

Revised: 12/22/2017 Rev: 4

Made In China

Document #281