

**Scotch®**

High Tack Box Sealing Tape 371+

# Ultimate champion.

Superior performance  
even on highly recycled  
corrugated boxes.



**3M**

# Unmatched adhesion to seal even the toughest boxes.



## Scotch® High Tack Box Sealing Tape 371+

Scotch® High Tack Box Sealing Tape 371+ provides a tamper-evident seal with the highest strength and durability in tough environments. You can be assured your boxes will stay closed throughout the supply chain no matter the percentage of recycled content — even in cold temperatures. Scotch® High Tack Box Sealing Tape 371+ is ideal for food and beverage, electronics and e-fullfillment industries.


### Features and benefits:

- Adheres to a variety of surfaces, including on corrugated boxes with 100% recycled content.
- Once applied, performs well at temperatures as low as 30°F (-1.1°C).
- Tamper-evident, clear tape can be custom printed to promote your brand.
- Quick, easy application by hand, manual dispensers or 3M-Matic™ Case Sealers.
- Available in 48mm and 72mm widths.


*“...the tape worked better in our case sealer, didn’t stick to the taping head, and not only was the initial tape tack successful, all the boxes stayed closed and went right into the freezer with no issues.”*

— Wholesale Dessert Manufacturer

## Tape 371+ knocks out the competition.

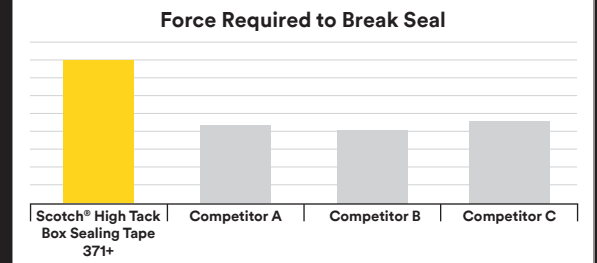

**Fiber Pull Demonstration:** Shows how much paper fiber the tape pulls off the box upon removal. The higher percent of fiber pull, the stronger the tape bond is to the box.

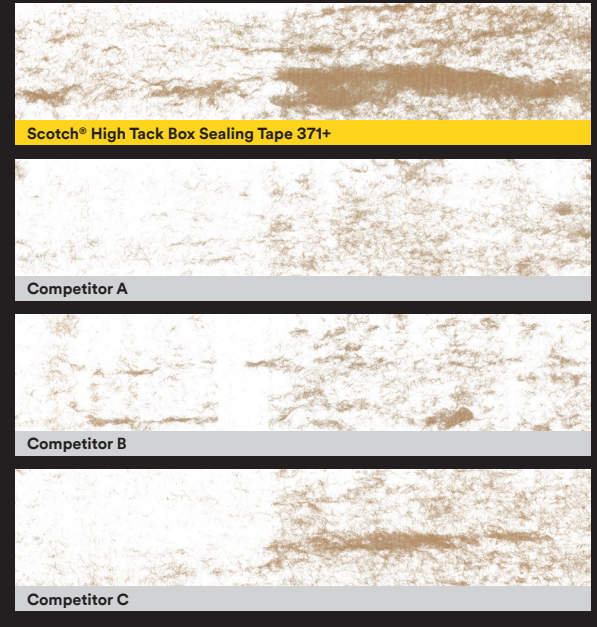

Product	Tape Structure (Backing/Adhesive)	Adhesion to Steel oz./in. (N/100mm)	Tensile Strength lbs./in. (N/100mm)	Elongation at Break (%)	Total Thickness mils (mm)	Available Color
<b>ASTM Test Method</b>		<b>D-3330</b>	<b>D-3759</b>	<b>D-3759</b>	<b>D-3652</b>	
<b>Scotch® High Tack Box Sealing Tape</b>						
<b>371+</b>	Polypropylene/Synthetic Rubber	42 (46)	22 (385)	160	1.9 (0.05)	Clear

**Note:** This technical information and data should be considered representative or typical only and should not be used for specification purposes.



**3M Industrial Adhesives and Tapes Division**  
**3M Center, Building 225-3S-06**  
**St. Paul, MN 55144-1000**

**Phone** 800-362-3550  
**Fax** 877-369-2923  
**Web** 3M.com/IATD

**Warranty and Limited Remedy:** 3M warrants that each 3M product meets the applicable 3M product specification at the time 3M ships the product. 3M MAKES NO OTHER EXPRESS OR IMPLIED WARRANTIES OR CONDITIONS, INCLUDING ANY IMPLIED WARRANTY OR CONDITION OF MERCHANTABILITY OR FITNESS FOR A PARTICULAR PURPOSE. If a 3M product does not conform to this warranty, the sole and exclusive remedy is, at 3M’s option, replacement of the 3M product or refund of the purchase price. **Limitation of Liability:** Except for the limited remedy above, and except to the extent prohibited by law, 3M will not be liable for any loss or damage arising from or related to the 3M product, whether direct, indirect, special, incidental, or consequential, regardless of the legal or equitable theory asserted.

Scotch is a registered trademark of 3M. 3M, 3M-Matic and the Plaid are trademarks of 3M.  
 © 3M 2018. All rights reserved. Please recycle 70-0710-0493-4.