

Midget Twist-Lock® Devices
 15A, 125/250V AC, 3 Pole, 3 Wire
 Non-Grounding
 Connector

HUBBELL



15A 125/250V
 NEMA ML-3R



Features

- Abuse resistant nylon housing
- Phenolic body for high heat resistance
- Angled body design for low profile in tight spaces

Ordering Information

Description	Cord Diameter	UPC	Catalog Number
Black straight connector.	.281-.421" (7.1-10.7)	783585237381	HBL7484

Listings

Listed to UL 498
 Certified to CSA C22.2 No.42

Specifications

Housing	Nylon
Contacts	Brass
Contact Holder	Phenolic
Terminal Screws	#5-40 Brass
Terminal Clamp	Zinc plated steel with black lacquer finish

Performance

Electrical


Current Interrupting Certified for current interrupting at full rated current
 Dielectric Voltage Withstands 2,000V minimum

Mechanical

Terminal Accomodation #18 AWG - #14 AWG stranded copper wire only.
 Terminal Identification Terminals identified in accordance with UL 498

Environmental

Flammability HB or better per UL94/CSA 22.2 No.0.17
 Moisture Resistance IP20 Suitability
 Operating Temperatures Maximum Continuous 75°C Minimum -40°C (w/o impact)

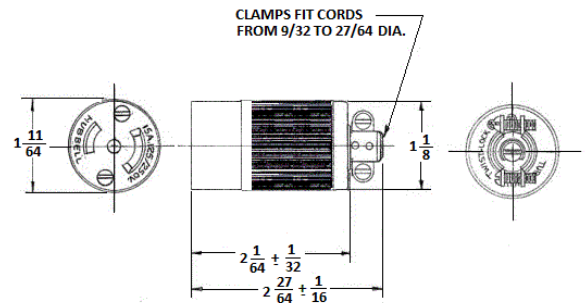

Accessories

Plug	HBL7485
Nylon Flanged Inlet	HBL7486N
Stainless Steel Flanged Inlet	HBL7486

Resources

Customer Use Drawing
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

