

# 6200 Series

★★★★  
**300lbs**  
Load Capacity  
Type IA  
Duty Rating

Back-up plates  
reinforce all top  
connections



Full line of Lock-In  
Accessories available

Non-Conductive  
side rails  
for working  
around electricity

Heavy duty  
internal spreaders

Fully braced  
rear horizontals

## THE LADDER OTHER LADDERS LOOK UP TO



HolsterTop® featuring Lock-In  
Accessory System allows you to  
customize your ladder top



Double riveted, fully braced  
slip-resistant steps




**EDGE®** bracing enhances strength  
and durability

# WERNER®



wernerladder.com

- HolsterTop® featuring Lock-In Accessory System allows you to customize your ladder top
- Double riveted, fully braced slip-resistant steps
- Heavy duty internal spreaders
- EDGE® bracing enhances strength and durability
- Shoe pads riveted to the EDGE® structure

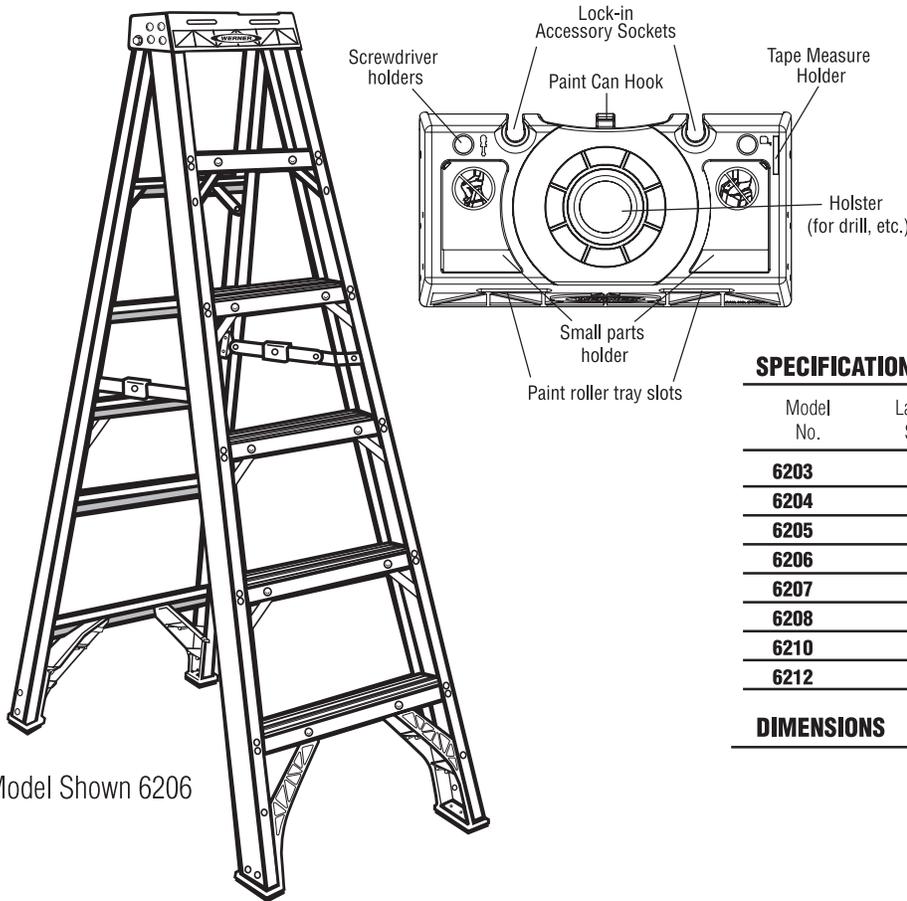

Model Shown 6206

★★★★  
**300 lbs.** LOAD CAPACITY  
*Includes User and Materials*  
 Type IA Duty Rating

### SPECIFICATIONS

Model No.	Ladder Size	Approx. Width	Approx. Spread	Approx. Cu. Ft.	Approx. Ship Wt.
<b>6203</b>	3'	18-1/8"	23-1/8"	2.0	13.0 lbs
<b>6204</b>	4'	19-7/8"	29"	3.0	16.0 lbs
<b>6205</b>	5'	21-5/8"	35-1/8"	4.1	19.0 lbs
<b>6206</b>	6'	23-3/8"	41-1/4"	5.3	22.0 lbs
<b>6207</b>	7'	25-1/8"	47-1/2"	6.6	26.0 lbs
<b>6208</b>	8'	26-7/8"	53-5/8"	8.1	30.0 lbs
<b>6210</b>	10'	30-3/8"	65-7/8"	12.5	39.0 lbs
<b>6212</b>	12'	33-7/8"	78-1/4"	15.0	48.0 lbs

### DIMENSIONS

Top: 5-3/4" x 13"      Steps: 3" wide  
 Front Rails: 3-1/8" wide      Rear Rails: 1-7/8" wide  
 Flange: 1-3/16" wide      Flange: 1-3/16" wide


## Lock-In Accessories

Exclusively with the  
**HolsterTop®**




**JobBucket**

AC50-JB-3

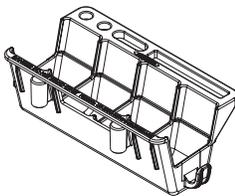


**JobCaddy**

AC54-JC

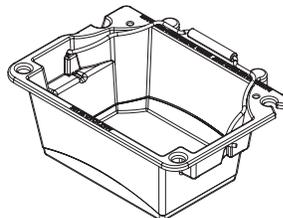

**UtilityBucket**

AC52-UB

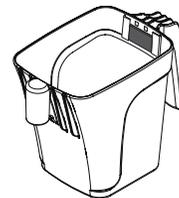


**PaintCup**

AC27-P



**ToolLasso®**

AC58-TL

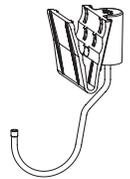

**UtilityHook**

AC56-UH