

Midget Twist-Lock® Devices
 15A, 125/250V AC, 3 Pole, 3 Wire
 Non-Grounding
 Valise® Plug

HUBBELL



15A 125/250V
 NEMA ML-3P



Features

- Fully insulated, abuse resistant nylon housing
- Insulation displacement terminals reduce wiring time
- Insulation displacement terminal
- Totally insulated body adds extra measure of safety

Ordering Information

Description	Cord Diameter	UPC	Catalog Number
Black Valise® plug.	.300"-.430" (7.6-10.9)	783585237435	HBL7485V

Listings


Listed to UL 498
 Certified to CSA C22.2 No.42
 Fed Spec W-C-596

Specifications

Housing	Nylon
Blades	Brass
Insulation Displacement Terminals	Brass
Body Holding Screws	Steel - Zinc plated

Performance

Electrical	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum
Mechanical	
Terminal Accomodation	#18 AWG - #14 AWG stranded copper wire only.
Terminal Identification	Terminals identified in accordance with UL 498
Environmental	
Flammability	HB or better per UL94/CSA 22.2 No.0.17
Moisture Resistance	IP20 Suitability
Operating Temperatures	Maximum Continuous 75°C Minimum -40°C (w/o impact)

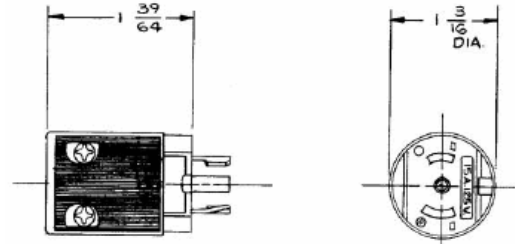

Accessories

Valise® Connector	HBL7484V
Nylon Flanged Receptacle	HBL7478N
Stainless Steel Flanged Receptacle	HBL7487
StainlessSteel Flanged Receptacle with Covered Terminals	HBL7489

Resources

Customer Use Drawing
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

